


## Product Description

For the benefits, refer to SKINTOP® MS

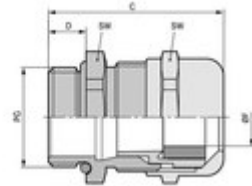

## Application range

- With reducing seal insert, to seal cables with smaller outer diameters.

## Benefits

- For the benefits, refer to SKINTOP® MS

## Design

- PG connection thread

## Note

- Refer to SKINTOP® PG accessories for suitable accessories
- Counter nut to be used: SKINDICHT® SM



Technical Data

**Caution**

Refer to Appendix T21 for the installation dimensions and torques

**Material**

Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR

**Protection rating**

IP 68 - 5 bar

**Temperature range**

-30°C to +100°C

Article List

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINTOP® MSR						
52015770	MSR 7	2 - 5	14	25.0	5.0	100
52015780	MSR 9	2 - 6	17	29.0	6.0	100
52015790	MSR 11	3 - 7	20	32.0	6.0	50
52015800	MSR 13,5	4 - 9	22	34.0	6.5	50
52015810	MSR 16	6 - 13	24	35.0	6.5	50
52015820	MSR 21	8 - 16	30	40.0	7.0	25
52015830	MSR 29	10,5 - 20	40	48.0	8.0	25
52015831	MSR 36	19 - 26	50	62.0	15.0	10
52015832	MSR 42	24 - 31	57	62.0	15.0	5
52015833	MSR 48	28 - 35	64	62.0	15.0	5

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.