


# COMMUNICATION & CONTROL

## MULTICONDUCTOR, FOIL SHIELD

PP, PE, PVC/PVC

UL TYPE CM  
CSA CMG FT4  
300 VOLT

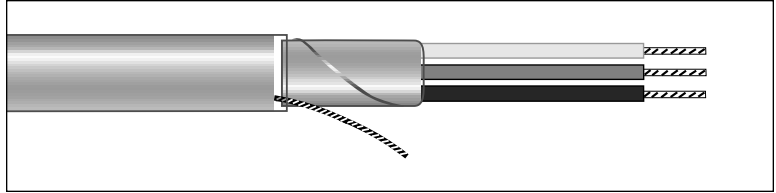

Alpha Part No.	No. of Cond.	Conductor		Insulation Thickness		Jacket Thickness		Diameter		Color Code	
		AWG	Strand	Material	Inches	mm	Inches	mm	Inches		mm
▲ 2464C	4	22	7/30	PP	0.008	0,20	0.020	0,51	0.16	4,1	2,3-shield 1,4-unshield
▲▲ 1243/3C	3	20	7/28	PE	0.014	0,35	0.029	0,73	0.21	5,3	2,3-shield 1-unshield
2465C	4	20	7/28	PVC	0.015	0,38	0.030	0,76	0.23	5,9	2,3-shield 1,4-unshield
▲▲▲ 2460C	2	22	Solid	PP	0.008	0,20	0.018	0,45	0.13	3,4	2,3-shield
▲ 2461C	2	22	7/30	PP	0.008	0,20	0.020	0,50	0.13	3,4	2,3-shield

## CHARACTERISTICS

### OPERATING TEMPERATURE:

- -20°C to 80°C – AWM
- 75°C – CM

### VOLTAGE RATING:

- 300 Volt

### COLOR DESCRIPTION:

 
 
- Color Code: 1-White, 2-Black, 3-Red, 4-Green
- Jacket Color: Gray

### PRODUCT DESCRIPTION:

- Conductor: Stranded Tinned Copper
- Insulation: Color-Coded PVC, Polypropylene (PP) or Polyethylene (PE)
- Shield: Aluminum/Polyester, Foil Facing Outward
- Drain Wire: Stranded Tinned Copper
- Jacket: PVC

## SPECIFICATIONS

- UL Type CM
- CSA CMG FT4
- Passes UL Vertical Tray Flame Test
- "C" Suffix Indicates CM Rating



Underwriters Laboratories Inc. Canadian Standards Association

## AVAILABILITY

- 100 ft (30,5m), 500 ft (152m), 1000 ft (305m) put-ups
- ▲ 100 ft (30,5m), 500 ft (152m), 1000 ft (305m)  
1000 ft (305m) boxed put-ups
- ▲▲ 1000 ft (305m)
- ▲▲▲ 100 ft (30,5m), 500 ft (152m), 1000 ft (305m),  
500 ft (152m) boxed put-ups



Toll Free: 1-800-52 ALPHA • Telephone: 908-925-8000 • Fax: 908-925-6923  
Europe/UK Telephone: +44 (0) 1932 772422 • Europe/UK Fax: +44 (0) 1932 772433

Web Site: [www.alphawire.com](http://www.alphawire.com)  
Email: [info@alphawire.com](mailto:info@alphawire.com)