


3M™ Static Dissipative Rubber Mats and Runners 6800 Series

When looking for a durable low-cost, dual layer rubber mat, look no further than the 3M Static Dissipative Rubber Mats and Runners 6800 Series. The 3M 6800 matting provides durability you expect from a dual layer rubber mat at a very competitive cost. Featuring a smooth finish, the 3M 6800 Series mat is available in Blue/Black and Gray/Black colors, and features standard sizes in 2 feet, 3 feet and 4 feet widths and 50 feet lengths. In addition, the 6800 mats are also available as 2 feet x 4 feet cut mats in Blue/Black and Gray/Black, including snaps only.

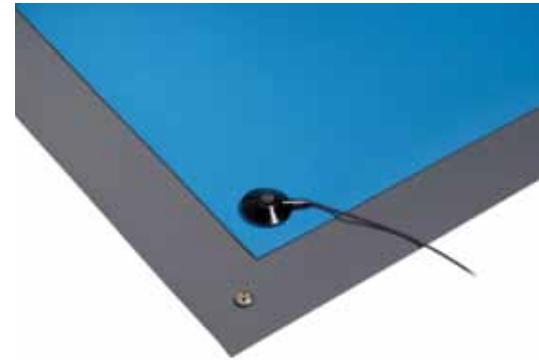

Product Bulletin

Properties	Typical Value
Material	Nitrile
Thickness	0.065 in. (1,7 mm)
Hardness	65 Shore A
Width	± .25 in.
*Resistance	
Surface to Ground (RTG)	< 10 ⁹ ohms
Surface to Surface (RTT)	< 10 ⁹ ohms

***Material Might have slight color and texture variance between lots*
***Mat Rolls need to be unrolled before being cut. When rolled some shrinkage may occur. Please allow time for mat to relax at room temperature 24-48 hours prior to cutting.*
Roll Width Tolerance: +/- .25 inches
Cut Mats Have a Tolerance of +/- .25 inches on width and length.

*Tested per ESD Association Standard S4.1.

Product

3M Stock ID	Product	Description	Size (ft)	(m)
80001389826	6810	Dissipative Rubber Table Mat, Gray	2 x 4	(0.6 x 1.2)
80001389834	6811	Dissipative Rubber Table Mat, Blue	2 x 4	(0.6 x 1.2)
80001389842	6840	Dissipative Rubber Table Runner, Gray	2 x 50	(0.6 x 7.3)
80001389859	6841	Dissipative Rubber Table Runner, Blue	2 x 50	(0.6 x 7.3)
80001389883	6860	Dissipative Rubber Table Runner, Gray	3 x 50	(0.9 x 15.2)
80001389891	6861	Dissipative Rubber Table Runner, Blue	3 x 50	(0.9 x 15.2)
80001389909	6870	Dissipative Rubber Table Runner, Gray	4 x 50	(1.2 x 15.2)
80001389917	6871	Dissipative Rubber Table Runner, Blue	4 x 50	(1.2 x 15.2)



3M is a trademark of 3M Company.

Important Notice

All statements, technical information, and recommendations related to 3M's products are based on information believed to be reliable, but the accuracy or completeness is not guaranteed. Before using this product, you must evaluate it and determine if it is suitable for your intended application. You assume all risks and liability associated with such use. Any statements related to the product which are not contained in 3M's current publications, or any contrary statements contained on your purchase order shall have no force or effect unless expressly agreed upon, in writing, by an authorized officer of 3M.

Warranty; Limited Remedy; Limited Liability.

This product will be free from defects in material and manufacture for a period of one year from the time of purchase. **3M MAKES NO OTHER WARRANTIES INCLUDING, BUT NOT LIMITED TO, ANY IMPLIED WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE.** If this product is defective within the warranty period stated above, your exclusive remedy shall be, at 3M's option, to replace or repair the 3M product or refund the purchase price of the 3M product. **Except where prohibited by law, 3M will not be liable for any indirect, special, incidental or consequential loss or damage arising from this 3M product, regardless of the legal theory asserted.**



Electronic Solutions Division Static Control Products

926 JR Industrial Drive
Sanford, NC 27332-9733
Toll-Free: 866-722-3736
International: 919-718-0000
Email: 3mstaticinfo@mmm.com
www.3Mstatic.com

Please recycle. Printed in U.S.A.
© 3M 2012. All rights reserved.
98-0799-1082-8