





Distanzhülsen Messing

- **Material:** Messingrohr, vernickelt
- **Optionen:** andere Längen, andere Aussen-Ø D
andere Innen-Ø d

Für Schraube	M 2	M 2,5	M 3	M 4	M 5	M 6
	Ø D = 4,0	Ø D = 4,5	Ø D = 6,0	Ø D = 8,0	Ø D = 10,0	Ø D = 11,0
	Ø d = 2,2	Ø d = 2,6	Ø d = 3,2	Ø d = 4,3	Ø d = 5,4	Ø d = 6,4

L	Bestell-Nr.					
1,0	5.51.013	5.52.013	5.53.013	5.54.013	5.55.013	5.56.013
1,5	5.51.015	5.52.015	5.53.015			
2,0	5.51.023	5.52.023	5.53.023	5.54.023	5.55.023	
3,0	5.51.033	5.52.033	5.53.033	5.54.033	5.55.033	5.56.033
3,2			5.53.032			
4,0	5.51.043	5.52.043	5.53.043	5.54.043		5.56.043
5,0	5.51.053	5.52.053	5.53.053	5.54.053	5.55.053*	5.56.053
6,0	5.51.063	5.52.063	5.53.063	5.54.063	5.55.063	
7,0	5.51.073	5.52.073	5.53.073	5.54.073	5.55.073	5.56.073
8,0	5.51.083	5.52.083	5.53.083	5.54.083	5.55.083	5.56.083
8,5		5.52.085				
9,0	5.51.093	5.52.093	5.53.093			5.56.093
10,0	5.51.103	5.52.103	5.53.103	5.54.103	5.55.103	5.56.103
12,0	5.51.123		5.53.123	5.54.123		5.56.123
13,0	5.51.130		5.53.130			
13,5	5.51.133	5.52.133	5.53.133			
14,0			5.53.143	5.54.143		
15,0	5.51.153	5.52.153	5.53.153	5.54.153	5.55.153	5.56.153
16,0			5.53.163	5.54.163		5.56.163
17,0						5.56.173
17,5	5.51.173		5.53.173			
18,0	5.51.183		5.53.183	5.54.183	5.55.183	
19,0				5.54.193		5.56.193
20,0	5.51.203	5.52.203	5.53.203	5.54.203	5.55.203	5.56.203
22,0			5.53.223			5.56.223
23,5			5.53.233			
24,0			5.53.243			
25,0			5.53.253	5.54.253	5.55.253	5.56.253
28,0			5.53.283			
30,0			5.53.303	5.54.303	5.55.303	5.56.303
35,0			5.53.353	5.54.353	5.55.353	5.56.353
40,0				5.54.403	5.55.403	5.56.403
50,0				5.54.503	5.55.503	5.56.503

* d = 5,3

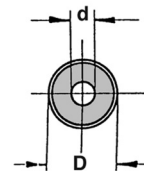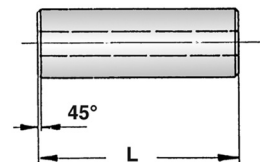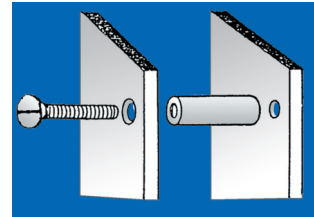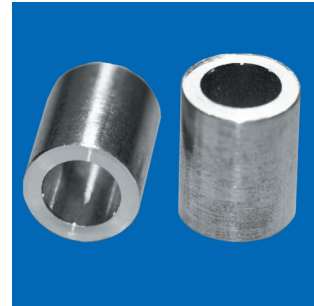

Distanzhülsen Messing

- **Material:** Messingrohr
- **Oberfläche:** vernickelt

Der Innendurchmesser ist nur für die angegebenen Schrauben ausgelegt.

Länge L	Masse in mm		
	M 3	M 7	M 10
	Ø D = 4,5	Ø D = 10,0	Ø D = 13,0
	Ø d = 3,4	Ø d = 7,2	Ø d = 10,2
Länge L	Bestell-Nr.		
2,0		62.70.072	62.71.102
3,0	5.50.033		62.71.103
4,0		62.70.074	62.71.104
5,0	5.50.053		
6,0		62.70.076	62.71.106
7,0	5.50.073		
8,0		62.70.078	62.71.108
10,0	5.50.103		62.71.110
20,0	5.50.203		
50,0	5.50.503		

