

- Replacement for incandescent 35 W
- Up to 85% energy saving
- Lifetime of 30,000 hrs
- An energy efficient LED solution for general lighting. Suitable for all fields of application of 35 W lamps.



Order Code 52110

General Data

Lamp Socket E27
Design Frosted

Geometric Data

Length (mm) 112
Diameter (mm) 60
Weight (g) 155

Electric Data


Wattage (W) 6
Voltage (V) 220-240
Power Factor ≥ 0.40
Operating Frequency (Hz) 50-60

Photometric Data

Luminous Flux (lm) 380
CRI ≥ 80
CCT (K) 3000 – warm white
Luminous Intensity (cd) -
Beam Angle (°) -
Lifetime (hrs) 30,000

Switching cycle 20,000

Wattage Equivalent (W) 35

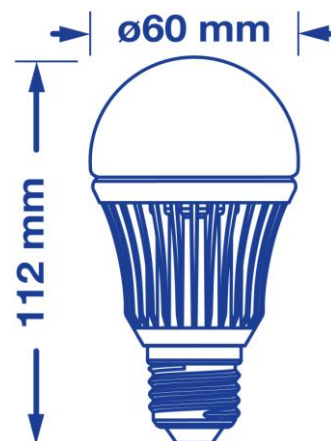



Order Code	52110
Product Description	LED CLASSIC A E27 6W 3000K WW 380LM Blister

Technical Packaging Details

Barcode	023942521105
EAN 128	(02)00023942521105(37)04(91)204
EAN 14	50023942521100
Pack Dimensions (HxWxL)	198 mm x 118 mm x 61 mm
Pack Weight	160 g
Carton Qty (Shipping Unit)	4
Carton Dimensions (HxWxL)	208 mm x 135 mm x 248 mm
Cartons/Layer	24
Layers/Pallet	4
Units/Pallet	384

Photometric Diagram

52110

