

- Replacement for incandescent 60 W
- Up to 85% energy saving
- Lifetime of 30,000 hrs
- An energy efficient LED solution for general lighting. It is the ideal light source for all fields of application of 60 W lamps.



Order Code 52115

General Data

Lamp Socket B22

Design Frosted

Geometric Data

Length (mm) 110

Diameter (mm) 60

Weight (g) 171

Electric Data

Wattage (W) 10

Voltage (V) 220-240

Power Factor ≥ 0.90

Operating Frequency (Hz) 50-60

Photometric Data

Luminous Flux (lm) 820

CRI ≥ 80

CCT (K) 3000 – warm white


Luminous Intensity (cd) -

Beam Angle (°) -

Lifetime (hrs) 30,000

Switching cycle 20,000

Wattage Equivalent (W) 60

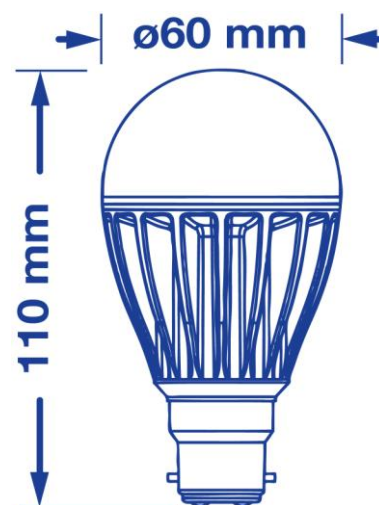



Order Code	52115
Product Description	LED CLASSIC A B22 10W 3000K WW 820LM Blister

Technical Packaging Details

Barcode	023942521150
EAN 128	(02)00023942521150(37)04(91)204
EAN 14	50023942521155
Pack Dimensions (HxWxL)	198 mm x 118 mm x 61 mm
Pack Weight	196 g
Carton Qty (Shipping Unit)	4
Carton Dimensions (HxWxL)	208 mm x 135 mm x 248 mm
Cartons/Pallet	96
Layers/Pallet	4
Units/Pallet	384

Photometric Diagram

52115

