




## Standard Polyethylene Spiral Binding for general applications

### • SBPE

#### Features and Benefits

SBPE spiral binding of polyethylene is used for organising and protecting cables and hoses for general applications. Due to the spiral structure, spiral binding can be applied to cables or hoses in situ. Cables can branch out at any point and in any direction. SBPE spiral binding is available in a wide range of diameters and colours.

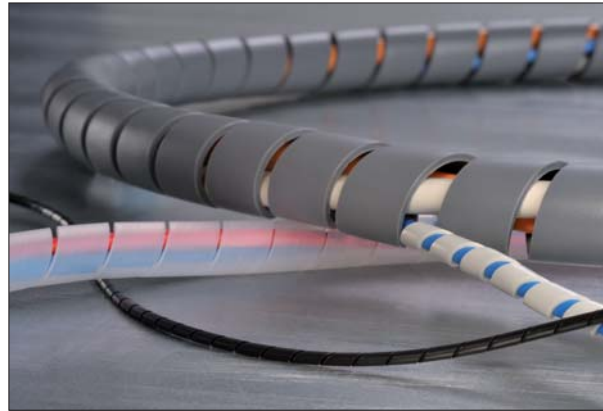




Spiral binding SBPE.

#### Application

SBPE spiral binding is particularly suitable for the applications in electrical industries, panel building and plant engineering. The 30-m-packaging is used for industrial applications. For smaller requirements SBPE spiral binding is also available in practical 5 metre lengths for sizes 4 and 9.

Material Data		
Material		<b>Polyethylene (PE)</b>
Operating Temperature		<b>-60 °C to +90 °C, intermittent +120 °C</b>
Flammability		<b>UL94 HB</b>

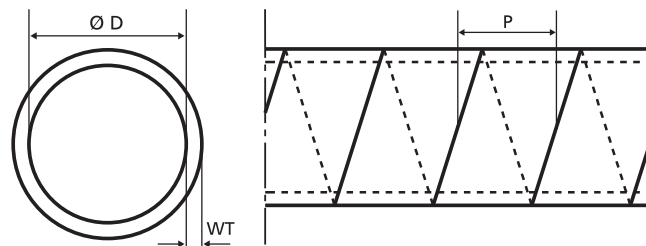

Technical Table

Article-No.	Type	Ø D	Wall (WT)	Pitch (P)	Bundle Ø min.	Bundle Ø max.	Colour
SBPE, 5 m - Lengths							
161-41103	<b>SBPE4D</b>	4.0	1.0	7.8	5.0	20.0	Natural (NA)
161-41104	<b>SBPE4D</b>	4.0	1.0	7.8	5.0	20.0	Black (BK)
161-41105	<b>SBPE4D</b>	4.0	1.0	7.8	5.0	20.0	Grey (GY)
161-41203	<b>SBPE9D</b>	9.0	1.4	12.5	10.0	100.0	Natural (NA)
161-41204	<b>SBPE9D</b>	9.0	1.4	12.5	10.0	100.0	Black (BK)
161-41205	<b>SBPE9D</b>	9.0	1.4	12.5	10.0	100.0	Grey (GY)
SBPE 30m lengths							
161-41000	<b>SBPE1.5</b>	1.5	0.8	6.0	1.6	8.0	Natural (NA)
161-41001	<b>SBPE1.5</b>	1.5	0.8	6.0	1.6	8.0	Black (BK)
161-41002	<b>SBPE1.5</b>	1.5	0.8	6.0	1.6	8.0	Grey (GY)
161-41100	<b>SBPE4</b>	4.0	1.0	7.8	5.0	20.0	Natural (NA)
161-41101	<b>SBPE4</b>	4.0	1.0	7.8	5.0	20.0	Black (BK)
161-41102	<b>SBPE4</b>	4.0	1.0	7.8	5.0	20.0	Grey (GY)
161-41200	<b>SBPE9</b>	9.0	1.4	12.5	10.0	100.0	Natural (NA)
161-41201	<b>SBPE9</b>	9.0	1.4	12.5	10.0	100.0	Black (BK)
161-41202	<b>SBPE9</b>	9.0	1.4	12.5	10.0	100.0	Grey (GY)
161-41300	<b>SBPE16</b>	16.0	1.6	16.0	20.0	150.0	Natural (NA)
161-41301	<b>SBPE16</b>	16.0	1.6	16.0	20.0	150.0	Black (BK)
161-41302	<b>SBPE16</b>	16.0	1.6	16.0	20.0	150.0	Grey (GY)

All dimensions in mm. Subject to technical changes.