


SACC-MS-4QO-0,34-M SCO

Order No.: 1521575

<http://eshop.phoenixcontact.net/phoenix/treeViewClick.do?UID=1521575>

Sensor/actuator connector, plug, straight, 4-pos., M12 SPEEDCON, A-coded, QUICKON-ONE, metal knurl, cable diameter max. 6 mm



Commercial data	
EAN	 4 017918 953072
Pack	1 pcs.
Customs tariff	85366990
Gross weight in pieces	0.01342 KG
Net weight per piece (exclusive packing)	0.01316 KG
Catalog page information	Page 73 (PC-2011)

Product notes

WEEE/RoHS-compliant since:
06/01/2005

<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

General data

Rated current at 40°C	4 A
Rated voltage	125 V
Number of positions	4
Volume resistance	≤ 5 mΩ

Insulation resistance	≥ 100 MΩ
Ambient temperature (operation)	-25 °C ... 80 °C (Plug / socket)
Ambient temperature (assembly)	-5 °C ... 50 °C (During assembly)

General characteristics

Standards/regulations	M12 plug-in connector IEC 61076-2-101
Coding	A - standard
Surge voltage category	II
Pollution degree	3
Degree of protection	IP65/67
Insertion/withdrawal cycles	≥ 100
Torque	0.4 Nm (M12 knurl) 0.8 Nm (Pressure nut)
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	TPU
Material of grip body	PA 6
Material, knurls	Zinc die-cast, nickel-plated
Sealing material	NBR
Connection method	Insulation displacement connection
Conductor cross section	0.14 mm ² ... 0.34 mm ²
AWG conductor cross section	26 ... 22
Assembly instructions	AWG 20 conductor cross section upon request
Wire diameter including insulation	0.7 mm ... 1.6 mm
Frequency of connections between conductors of the same cross section	10
External cable diameter	3.5 mm ... 6 mm
Wire insulation material	PVC / PE
Wrench size, union nut	13 mm
Structure of individual litz in acc. with VDE 0295 / smallest wire diameter	Class 2-6
Status display	No

Certificates / Approvals



Certification cULus Recognized, GOST

Certifications applied for:

Certification Ex:

Accessories


Item	Designation	Description
Cable/conductor		
1501692	SAC-4P-100,0-PUR/0,25	Cable ring, PUR halogen-free black, 4-pos., conductor colors: brown / white / blue / black, cable length: 100 m
1501663	SAC-4P-100,0-PUR/0,34	Cable ring, PUR halogen-free black, 4-pos., conductor colors: brown / white / blue / black, cable length: 100 m

Protection and sealing elements		
1430873	PROT-M12 FS-PA-CHAIN	M12 sealing cap made of plastic with fixing band, for sensor cables, for free M12 sockets

Tools		
1208432	SAC BIT M12-D15	Nut for assembling sensor/actuator cables with M12 connector and for M12 connectors with QUICKON fast connection technology, for 4 mm hexagonal drive
1212033	SAC BIT QUICKON-W13	Nut for assembling QUICKON pressure nuts with 13 mm wrench size, for 4 mm hexagonal drive
1208429	TSD 04 SAC	Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors
1212224	TSD-M 1,2NM	Torque screw driver, accuracy as per EN ISO 6789 standard, adjustable from 0.3 - 1.2 Nm
1212600	TSD-M SAC-BIT ADAPTER	Adapter bit for TSD-M...torque tools, E6.3-1/4" drive with 4 mm hexagon to accommodate SAC bits

Diagrams/Drawings


Dimensioned drawing

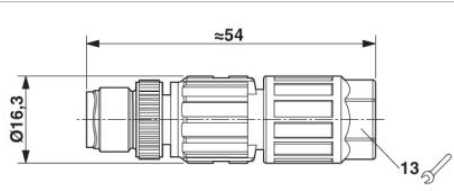

M12 x 1 plug, straight

Schematic diagram

Pin assignment M12 plug, 4-pos., A-coded, view plug side

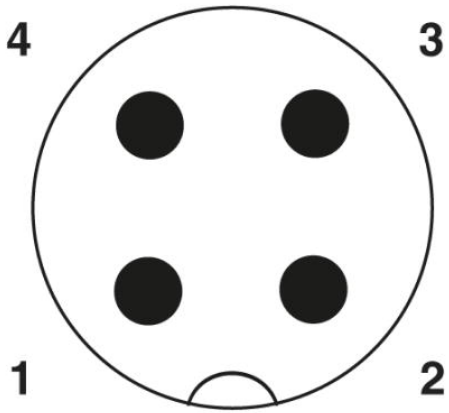

Address

PHOENIX CONTACT Ltd
Halesfield 13
Telford Shropshire TF7 4PG,GB
Phone 01952 681 700
Fax 01952 681 799
<http://www.phoenixcontact.co.uk>



© 2013 Phoenix Contact
Technical modifications reserved;