

U.I. Lapp GmbH	PRODUCT INFORMATION	
	SKINDICHT® MINI	12.09.2012

High degree of protection
 For the smallest conductor sizes
 Low height
 Gentle cable clamping
 High packing density



Application range

For use wherever there is limited assembly space.
 Sensors
 Measuring technology

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Technical Data

Material:	Body: nickel-plated brass Seal: CR/NBR
Protection rating:	IP 68
Temperature range:	-20°C to +100°C

Product Management	Document: LAPP_PRO1017EN.pdf	1 / 3
--------------------	------------------------------	-------




SKINDICHT® MINI

12.09.2012

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINDICHT® MINI						
52001860	MINI 6 x 1	2 - 3	9	19,5	5.0	50
52001880	MINI 8 x 1	3,5 - 5,5	11	20,5	5.0	50

U.I. Lapp GmbH	PRODUCT INFORMATION	 LAPP GROUP
	SKINDICHT® MINI	12.09.2012

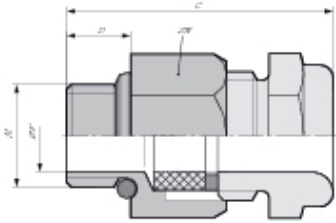

Product Management	Document: LAPP_PRO1017EN.pdf	3 / 3
--------------------	------------------------------	-------