

## Series 034

### SUB-MINIATURE T-05 SPACE SAVER

This sub-miniature pushbutton switch offers high quality and reliability in a very small package. With gold contacts, this switch offers up to 1,000,000 cycles. This switch is ideal for applications where PC board space is at a premium.

### APPLICATIONS

- Reset switch
- Detect switch



### KEY FEATURES:

- Momentary action
- Gold contacts
- PC terminals
- SPST-NO (Form A) circuitry
- Variety of actuator lengths
- Up to 1,000,000 mechanical actuations

ACTUAL SIZE


### ORDERING INFORMATION:

Part Number	Button Height
034-550-001	0.06
034-550-002	0.50
034-550-005	0.15
034-550-006	0.25
034-550-010	0.37
034-550-015	0.19


### STANDARDS / AGENCY / RATINGS:




**034-550-001**

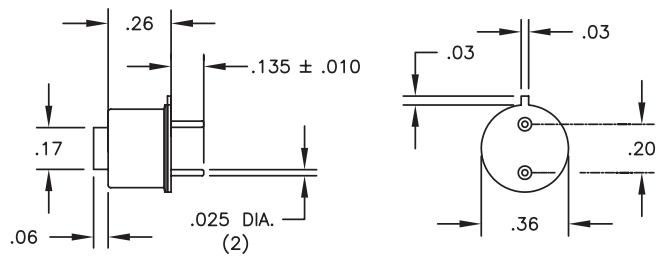


**034-550-002**

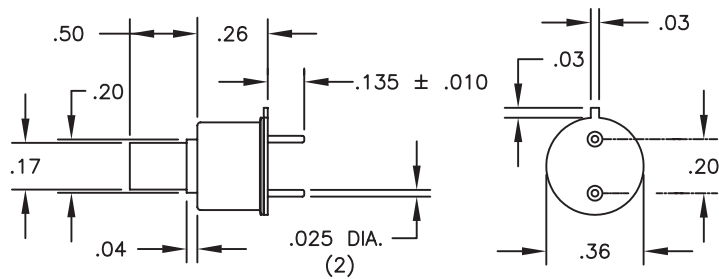


**034-550-005**

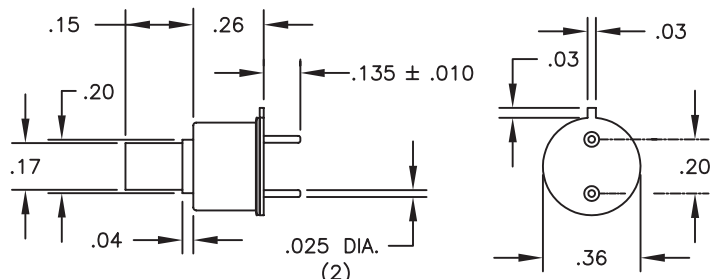


**034-550-006**

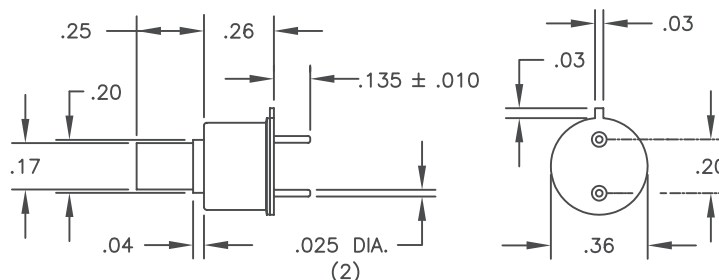

**034-550-015**

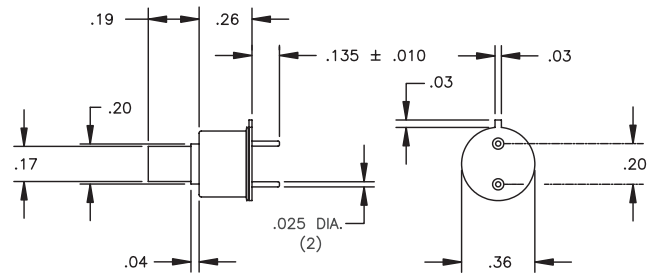

**034-550-010**

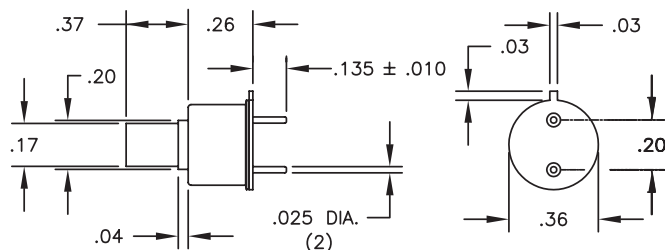

**MECHANICAL / ELECTRICAL CHARACTERISTICS:**

**Circuit:**

SPST-NO (Form A) Momentary

**Temperature rating:**

-30°C to +65°C  
(-22°F to +149°F)

**Life (mechanical):**

1,000,000 actuations

**Contact rating:**

100 mA @ 125 VAC

**Actuator:**

thermoplastic (PBTP)

**Can:**

Nickel-silver

**Contacts & terminals:**

gold over nickel plate