


# Sta-Kon®

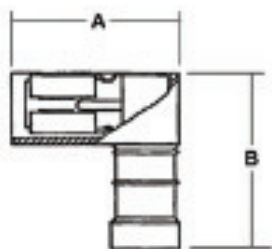

**Disconnects**

**T&B Catalog Number:**

RB14-250A

**UPC Number:**

78621085676

**Status:**

Active

**Description:**

Insulated Nylon Female - 250 Series Disconnects For Wire Range 16-14 Length 0.8, Tab Size .250 x .032 , Blue

**ABB Attributes**

Color Blue

**WEB\_USE**

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Unique construction of the female disconnect offers long-term dependability. Brazed seam serrated barrel provides maximum tensile strength.

**General**

Disconnect Type	Female - 250 Series
Insulation Type	Insulated Nylon
Terminal Series	RB
Material	Brass
Finish	Electro -Tin Plated
Color	Blue
Wire Range	16-14
Tab Size	.250 x .032

**Dimension Information**

Maximum Insulation (inches)	.200
A (inches)	.80
B (inches)	.72

**Specifications**

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

**Tooling**

Tool Charts	Available on Website
Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003
Recommended Tool	ERG4001

**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	250
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.56 lbs. per 100
Alternate Package Qty	RB2577F