



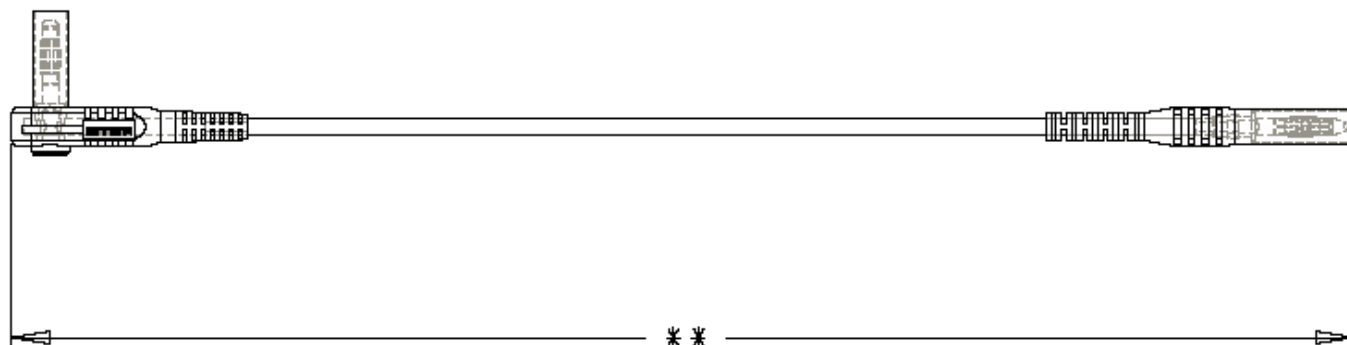

**Part Number:** BU-6162-M-\*\*-\*

**Description:** Right Angle Shrouded Banana Plug to Shrouded Banana Plug -Silicone

2607

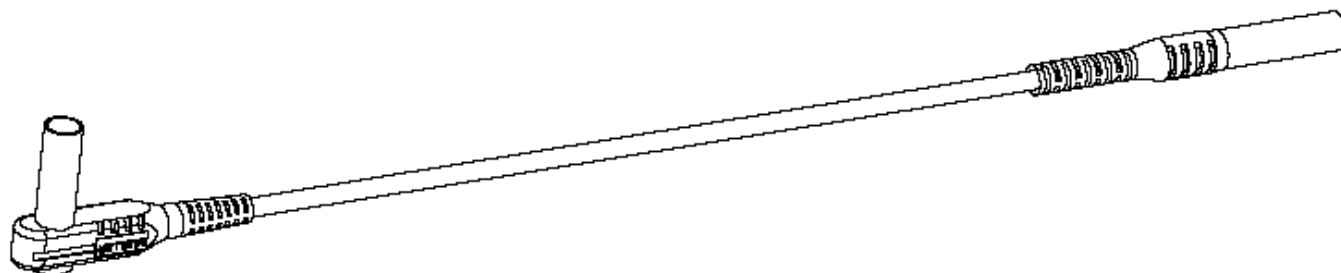

- **Right Angle Shrouded Banana Plug to Shrouded Banana Plug -Silicone**  
Compatible with 4mm banana jack
- Provide hands free testing up to 3 kV and 20 Amps
- **Material:**
  - Wire: #18 AWG (413/44), UL 3577, 105° C High Flex Silicone Jacket
  - Housing: High Temperature Nylon
  - Banana Plug: Nickel plated Brass
- Order as BU-6162-\*\*-\*, where “\*\*” is length and “\*” is the color
  - “\*\*” -Standard length is 39”
  - “\*” - Standard color are 0=Black and 2=Red
- Packaged in Bulk
- RoHS Compliant