

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [79576-2111](#)
Status: **Active**
Overview: iPass™
Description: Internal iPass™ Mini SAS Double-Ended Plug with Sidebands, 36 Circuits, 30 AWG, 0.30m Length, Controller-to-Controller, Pinout 2

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	79576
Connector to Connector	iPass-to-iPass
Overview	iPass™
Product Name	iPass™, Mini Multi-Lane, PCI Express*, SAS
UPC	822350138819

Physical

Cable Length	0.30m
Circuits (Loaded)	36
Color - Resin	Black, Natural
Gender	Plug
Lock to Mating Part	Yes
Material - Resin	Low Density Polyethylene, Polyester
Net Weight	56.120/g
Packaging Type	Bag
Single Ended	No
Termination Interface: Style	Crimp or Compression
Waterproof / Dustproof	No
Wire Insulation Diameter	N/A
Wire Size AWG	30
Wire/Cable Type	Twin-ax

Electrical

Shielded	No
----------	----

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-79576-200
---------------	--------------

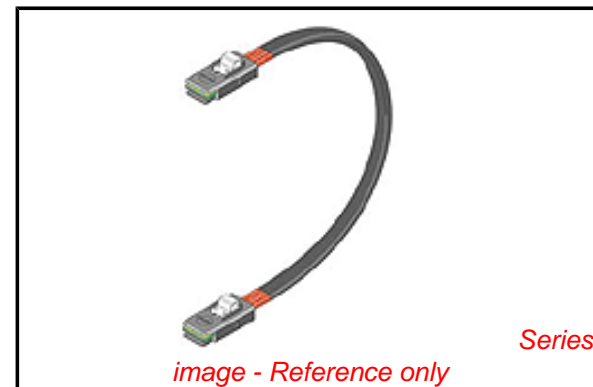


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[79576Series](#)

Mates With

[75783](#) iPass™ Right Angle Connector.
[75784](#) iPass™ Vertical Connector