

U.I. Lapp GmbH	<b>PRODUCT INFORMATION</b>	
	<b>SKINTOP® STR</b>	<b>12.09.2012</b>

High oil-resistance for maximum reliability  
 Permanent vibration protection  
 Optimum strain relief  
 Wide, variable clamping ranges  
 Various accessories (e.g. multiple sealing inserts)



### Application range

With reducing seal insert, to seal cables with smaller outer diameters.

### Design

PG connection thread

### Approvals (Norm references)

UL File Nr. E79903

### Note

Refer to SKINTOP® PG accessories for suitable accessories  
 Counter nut to be used: SKINTOP® GMP-GL

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.



### Technical Data

Caution:	Refer to Appendix T21 for the installation dimensions and torques
Colour delivered:	Silver grey (RAL 7001) Light grey (RAL 7035) Black (RAL 9005), UV-resistant
Material:	Body: Polyamide Seal: CR
Tests:	GGVS: TÜ.EGG.020-95
Protection rating:	Outdoors
Temperature range:	-20°C to +80°C

Product Management	Document: LAPP_PRO1067EN.pdf	1 / 4
--------------------	------------------------------	-------



## SKINTOP® STR


12.09.2012

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length inner mm	Pieces / PU
SKINTOP® STR silver grey						
53015100	STR 7	1,5 - 5	15	32.0	8.0	100
53015110	STR 9	2 - 6	19	36.0	8.0	100
53015120	STR 11	2 - 7	22	38.0	8.0	100
53015130	STR 13,5	4 - 9	24	41.0	9.0	100
53015140	STR 16	6 - 12	27	44.0	10.0	50
53015150	STR 21	9 - 16	33	49.0	11.0	50
53015160	STR 29	11 - 20	42	56.0	11.0	25
53015170	STR 36	17 - 26	53	66.0	13.0	10
53015180	STR 42	22 - 31	60	68.0	13.0	5
53015190	STR 48	26 - 35	65	69.0	14.0	5
SKINTOP® STR black						
53015300	STR 7	1,5 - 5	15	32.0	8.0	100
53015310	STR 9	2 - 6	19	36.0	8.0	100
53015320	STR 11	2 - 7	22	38.0	8.0	100
53015330	STR 13,5	4 - 9	24	41.0	9.0	100
53015340	STR 16	6 - 12	27	44.0	10.0	50
53015350	STR 21	9 - 16	33	49.0	11.0	50
53015360	STR 29	11 - 20	42	56.0	11.0	25
53015370	STR 36	17 - 26	53	66.0	13.0	10
53015380	STR 42	22 - 31	60	68.0	13.0	5
53015390	STR 48	26 - 35	65	69.0	14.0	5
SKINTOP® STR light grey						
53018100	STR 7	1,5 - 5	15	32.0	8.0	100
53018110	STR 9	2 - 6	19	36.0	8.0	100
53018120	STR 11	2 - 7	22	38.0	8.0	100
53018130	STR 13,5	4 - 9	24	41.0	9.0	100
53018140	STR 16	6 - 12	27	44.0	10.0	50
53018150	STR 21	9 - 16	33	49.0	11.0	50
53018160	STR 29	11 - 20	42	56.0	11.0	25
53018170	STR 36	17 - 26	53	66.0	13.0	10



Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length inner mm	Pieces / PU
53018180	STR 42	22 - 31	60	68.0	13.0	5
53018190	STR 48	26 - 35	65	69.0	14.0	5

U.I. Lapp GmbH	<b>PRODUCT INFORMATION</b>	 <b>LAPP GROUP</b>
<b>SKINTOP® STR</b>		12.09.2012

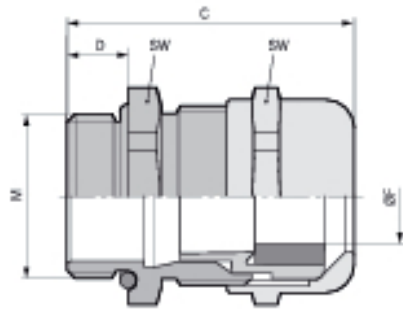

Product Management	Document: LAPP_PRO1067EN.pdf	4 / 4
--------------------	------------------------------	-------