



LabelManager® 500TS Specifications

| | |
|-----------------------------|--|
| Display | Large, full-color touch screen |
| Keyboard | QWERTY |
| Label customisation options | 10 fonts 25 font sizes 32 text styles 100s of built-in symbols/clip art |
| Labels | 6 mm, 9 mm, 12 mm, 19 mm, 24 mm |
| Memory | Store over 500 labels on your machine |
| Power | Rechargeable battery pack |
| Connectivity | USB, PC or Mac® |
| Dimensions | L 190 mm x W 165 mm x H 95 mm |
| Weight | 800 grams |

Compatible label widths and options

To learn more about DYMO® D1 labels, visit www.dymo.com



| Standard for general use | Permanent applications | Flexible for curved surfaces |
|---|---------------------------------|---------------------------------|
| Width 6, 9, 12, 19, 24 mm Length 7 m | Width 12, 19 mm Length 5,5 m | Width 12, 19 mm Length 3,5 m |
| | | |



Easy Peel backing for quick and easy application

Dealer:



©2011 DYMO / DYMO bvba, Industriepark-Noord 30 / B-9100 Sint-Niklaas - Belgique
UK / Ireland Newell Rubbermaid Halifax Avenue Fradley Park Lichfield WS13 8SS
www.dymo.com



Touch Screen Label Maker with PC or Mac® Connection

S0964710




1 Type



2 Touch



3 Print

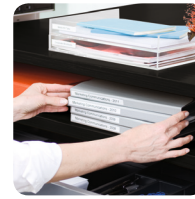

The first standalone office touch screen label maker from DYMO®.

Name anything you ever wanted to do with a label maker – the revolutionary DYMO Touch Screen™ label maker lets you do it with ease! Edit, format, and customise labels with a touch of your fingertip. Connect to your PC or Mac** and use DYMO Label™ software to customise your labels with fonts or graphics – even download your labels for editing and printing on the go.

LabelManager™ 500TS Features

- Large, full-color touch screen—a DYMO® first! Just tap to create, edit and format labels with ease
- Speed text entry using the computer-style keyboard with country-specific layout
- Eliminate the hassle of manual cutting with an automatic label cutter
- Customise your labels with 10 fonts, 25 font sizes, 5 boxes plus underline, 32 text styles and 100s of built-in symbols and clip art images
- Prints crystal clear graphics, barcodes and logos at 300 dpi resolution
- Share without losing your settings—new user profiles let you store settings and data for up to 5 different users
- Avoid the cost and waste of disposable batteries with the rechargeable battery pack
- Connect to your PC or Mac** and use DYMO Label™ software to customise your labels with fonts or graphics – even download your labels for editing and printing on the go
- Label fast – prints twice as fast as other DYMO® label makers



Scan with your smartphone to see the LabelManager™ 500TS video!



DYMO Label™ Software

DYMO Label™ Works with any fonts or graphics on your computer – customise with your company logo and much more!

Multi-application Print labels from within Microsoft® Word, Excel® or Outlook®, Mac® Address Book, QuickBooks® and other programs

***PC or Mac®** Works with Windows® XP, Windows Vista®, Windows® 7 or Mac OS® v10.4 or later

Package Includes

- LabelManager™ 500TS label maker
- D1 starter label cassette black on white, 24 mm x 3 m
- Rechargeable battery pack
- USB cable
- Quick Start and Reference Guides
- 2-Year Limited Warranty Card

www.dymo.com