


**PRODUCT
DATA SHEET**

Type	Size	Rating	Description	Part No.
Incandescent	T10	28V 60mA	T-3/4 Wedgebase Lamp	656-002LF

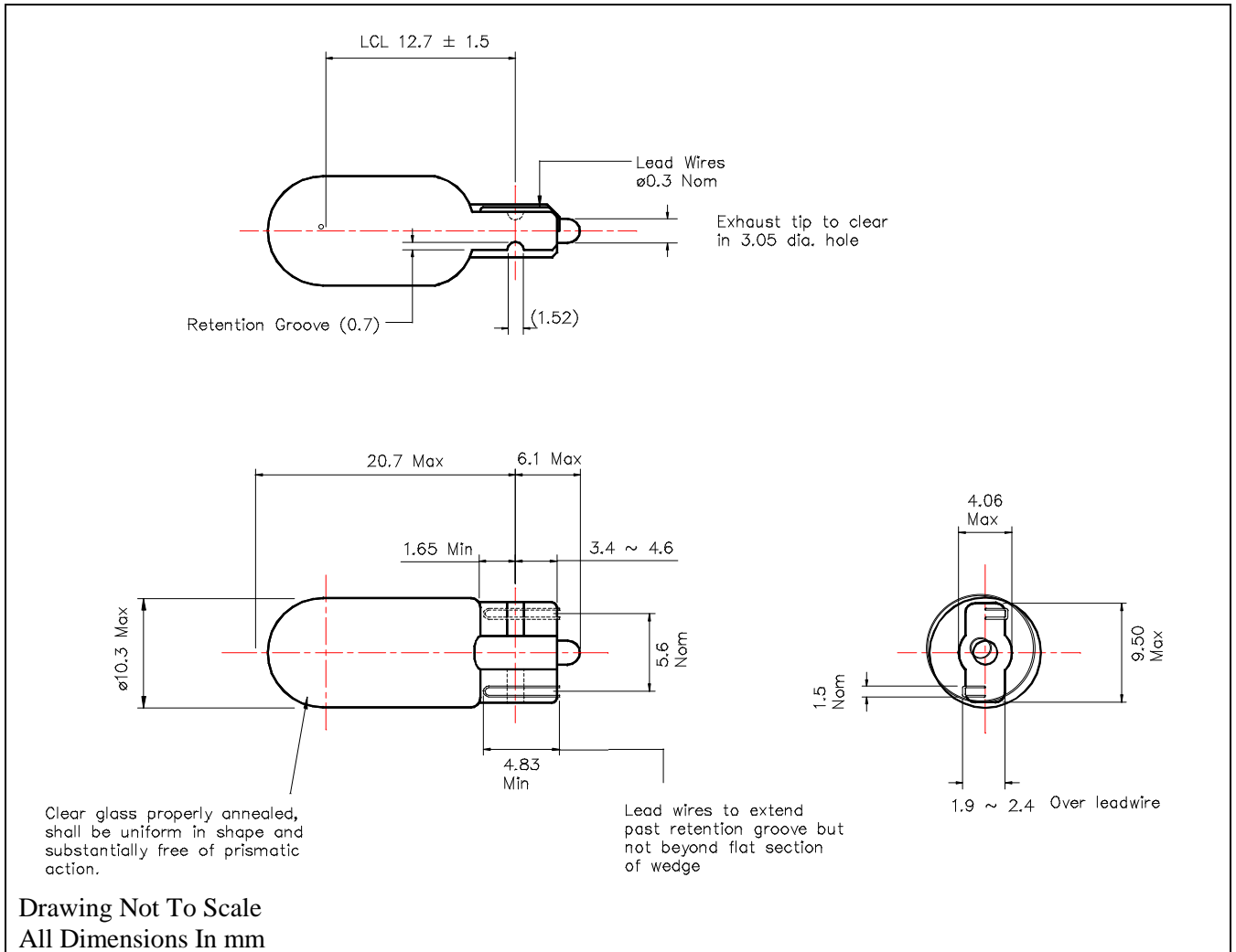

PHOTOMETRY DATA

TEST	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE (Hours)
	Min.	Nom.	Max.	Min.	Nom.	Max.	
VOLTS 28.0	54	60	66	5.8	7.8	9.8	2,500

NOTES:

- 1) W2.1x9.5d in accordance with IEC 61-1, (BS EN 60061-1)
- 2) C-2F filament shape.
- 3) Vacuum Lamp.
- 4) Lamp Marking: "VCH 656 28V 60mA ", to be durably printed on the bulb, below the level of the filament.
- 5) Lamp components are lead-free

Issue No.	Date	C.N. No.	Drawn	Tech	QA	M & P	Sales
1	06/08/04	-	BCW	Approved			