

# High Power Thick Film Resistor 0603



RoHS  
Compliant





## Features

- High power in standard size
- Suitable for both wave and reflow soldering
- Application : AV adapters, LCD back light, Camera strobe

## Performance Specification

Temperature Coefficient	: 1Ω to 10Ω ≤ ±200PPM/°C 11Ω to 10MΩ ≤ ±100PPM/°C
Short Time Overload	: ±5% : ±(2% +0.1Ω)Max. ±1% : ±(1% +0.1Ω)Max.
Terminal Bending	: ±(1% +0.05Ω) Max.
Soldering Heat	: ±(1% +0.05Ω) Max.
Solderability	: Min. 95% coverage
Temperature Cycling	: ±5% : ±(1% +0.05Ω) Max. ±1% : ±(0.5% +0.05Ω) Max.
Humidity (Steady State)	: ±5% : ±(3% +0.1Ω) Max. ±1% : ±(0.5% +0.1Ω) Max.
Load Life in Humidity	: ±5% : ±(3% +0.1Ω) Max. ±1% : ±(1% +0.1Ω) Max.
Load Life	: ±5% : ±(3% +0.1Ω) Max. ±1% : ±(1% +0.1Ω) Max.

## Dimension

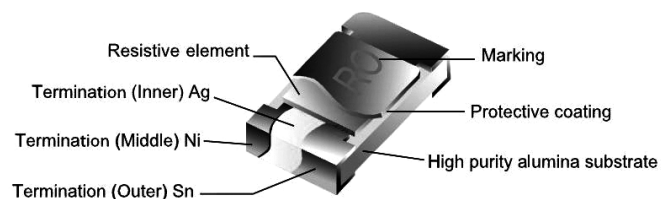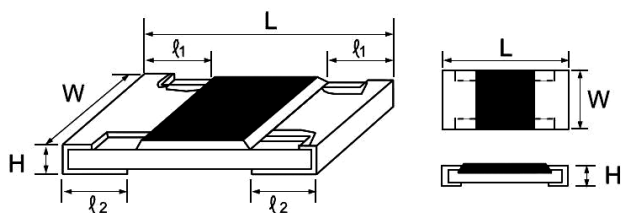

Type	Dimension (mm)					Resistance Range
	L	W	H	l <sub>1</sub>	l <sub>2</sub>	
0603	1.6 ±0.1	0.8 <sup>+0.15</sup> / <sub>+0.1</sub>	0.45 ±0.1	0.3 ±0.2	0.3 ±0.2	1Ω to 10MΩ

Type	Power Rating at 70°C	Max. Working Voltage	Max. Overload Voltage	Dielectric Withstanding Voltage	Tolerance %	Resistance Range
0603	1/5W	50V	100V	300V	±1% ±5%	1Ω to 10MΩ 1Ω to 10MΩ

# High Power Thick Film Resistor 0603



## Part Number Table

Description	Part Number	Description	Part Number
Resistor, 10R, 0603 1% 125mW	MCHP03W8F100JT5E	Resistor, 5K6, 0603 1% 125mW	MCHP03W8F5601T5E
Resistor, 12R, 0603 1% 125mW	MCHP03W8F120JT5E	Resistor, 6K8, 0603 1% 125mW	MCHP03W8F6801T5E
Resistor, 15R, 0603 1% 125mW	MCHP03W8F150JT5E	Resistor, 8K2, 0603 1% 125mW	MCHP03W8F8201T5E
Resistor, 18R, 0603 1% 125mW	MCHP03W8F180JT5E	Resistor, 10K, 1%, 125mW	MCHP03W8F1002T5E
Resistor, 22R, 0603 1% 125mW	MCHP03W8F220JT5E	Resistor, 12K, 0603 1% 125mW	MCHP03W8F1202T5E
Resistor, 27R, 0603 1% 125mW	MCHP03W8F270JT5E	Resistor, 15K, 0603 1% 125mW	MCHP03W8F1502T5E
Resistor, 33R, 0603 1% 125mW	MCHP03W8F330JT5E	Resistor, 18K, 0603 1% 125mW	MCHP03W8F1802T5E
Resistor, 39R, 0603 1% 125mW	MCHP03W8F390JT5E	Resistor, 22K, 0603 1% 125mW	MCHP03W8F2202T5E
Resistor, 47R, 0603 1% 125mW	MCHP03W8F470JT5E	Resistor, 27K, 0603 1% 125mW	MCHP03W8F2702T5E
Resistor, 56R, 0603 1% 125mW	MCHP03W8F560JT5E	Resistor, 33K, 0603 1% 125mW	MCHP03W8F3302T5E
Resistor, 68R, 0603 1% 125mW	MCHP03W8F680JT5E	Resistor, 39K, 0603 1% 125mW	MCHP03W8F3902T5E
Resistor, 82R, 0603 1% 125mW	MCHP03W8F820JT5E	Resistor, 47K, 0603 1% 125mW	MCHP03W8F4702T5E
Resistor, 100R, 0603 1% 125mW	MCHP03W8F1000T5E	Resistor, 56K, 0603 1% 125mW	MCHP03W8F5602T5E
Resistor, 120R, 0603 1% 125mW	MCHP03W8F1200T5E	Resistor, 68K, 0603 1% 125mW	MCHP03W8F6802T5E
Resistor, 150R, 0603 1% 125mW	MCHP03W8F1500T5E	Resistor, 82K, 0603 1% 125mW	MCHP03W8F8202T5E
Resistor, 180R, 0603 1% 125mW	MCHP03W8F1800T5E	Resistor, 100K, 0603 1% 125mW	MCHP03W8F1003T5E
Resistor, 220R, 0603 1% 125mW	MCHP03W8F2200T5E	Resistor, 120K, 0603 1% 125mW	MCHP03W8F1203T5E
Resistor, 270R, 0603 1% 125mW	MCHP03W8F2700T5E	Resistor, 150K, 0603 1% 125mW	MCHP03W8F1503T5E
Resistor, 330R, 0603 1% 125mW	MCHP03W8F3300T5E	Resistor, 180K, 0603 1% 125mW	MCHP03W8F1803T5E
Resistor, 390R, 0603 1% 125mW	MCHP03W8F3900T5E	Resistor, 220K, 0603 1% 125mW	MCHP03W8F2203T5E
Resistor, 470R, 0603 1% 125mW	MCHP03W8F4700T5E	Resistor, 270K, 0603 1% 125mW	MCHP03W8F2703T5E
Resistor, 560R, 0603 1% 125mW	MCHP03W8F5600T5E	Resistor, 330K, 0603 1% 125mW	MCHP03W8F3303T5E
Resistor, 680R, 0603 1% 125mW	MCHP03W8F6800T5E	Resistor, 390K, 0603 1% 125mW	MCHP03W8F3903T5E
Resistor, 820R, 0603 1% 125mW	MCHP03W8F8200T5E	Resistor, 470K, 0603 1% 125mW	MCHP03W8F4703T5E
Resistor, 1K, 1%, 125mW	MCHP03W8F1001T5E	Resistor, 560K, 0603 1% 125mW	MCHP03W8F5603T5E
Resistor, 1K2, 0603 1% 125mW	MCHP03W8F1201T5E	Resistor, 680K, 0603 1% 125mW	MCHP03W8F6803T5E
Resistor, 1K5, 0603 1% 125mW	MCHP03W8F1501T5E	Resistor, 820K, 0603 1% 125mW	MCHP03W8F8203T5E
Resistor, 1K8, 0603 1% 125mW	MCHP03W8F1801T5E	Resistor, 1M, 0603 1% 125mW	MCHP03W8F1004T5E
Resistor, 2K2, 0603 1% 125mW	MCHP03W8F2201T5E	Resistor, 1M2, 0603 1% 125mW	MCHP03W8F1204T5E
Resistor, 2K7, 0603 1% 125mW	MCHP03W8F2701T5E	Resistor, 1M5, 0603 1% 125mW	MCHP03W8F1504T5E
Resistor, 3K3, 0603 1% 125mW	MCHP03W8F3301T5E	Resistor, 1M8, 0603 1% 125mW	MCHP03W8F1804T5E
Resistor, 3K9, 0603 1% 125mW	MCHP03W8F3901T5E	Resistor, 2M2, 0603 1% 125mW	MCHP03W8F2204T5E
Resistor, 4K7, 0603 1% 125mW	MCHP03W8F4701T5E	Resistor, 2M7, 0603 1% 125mW	MCHP03W8F2704T5E

# High Power Thick Film Resistor 0603



Description	Part Number
Resistor, 3M3, 0603 1% 125mW	MCHP03W8F3304T5E
Resistor, 3M9, 0603 1% 125mW	MCHP03W8F3904T5E
Resistor, 4M7, 0603 1% 125mW	MCHP03W8F4704T5E
Resistor, 5M6, 0603 1% 125mW	MCHP03W8F5604T5E
Resistor, 6M8, 0603 1% 125mW	MCHP03W8F6804T5E
Resistor, 8M2, 0603 1% 125mW	MCHP03W8F8204T5E
Resistor, 10M, 0603 1% 125mW	MCHP03W8F1005T5E
Resistor, 1R, 0603 5% 125mW	MCHP03W8J010JT5E
Resistor, 12R, 0603 5% 125mW	MCHP03W8J0120T5E
Resistor, 15R, 0603 5% 125mW	MCHP03W8J0150T5E
Resistor, 18R, 0603 5% 125mW	MCHP03W8J0180T5E
Resistor, 22R, 0603 5% 125mW	MCHP03W8J0220T5E
Resistor, 27R, 0603 5% 125mW	MCHP03W8J0270T5E
Resistor, 33R, 0603 5% 125mW	MCHP03W8J0330T5E
Resistor, 39R, 0603 5% 125mW	MCHP03W8J0390T5E
Resistor, 47R, 0603 5% 125mW	MCHP03W8J0470T5E
Resistor, 56R, 0603 5% 125mW	MCHP03W8J0560T5E
Resistor, 68R, 0603 5% 125mW	MCHP03W8J0680T5E
Resistor, 82R, 0603 5% 125mW	MCHP03W8J0820T5E
Resistor, 100R, 0603 5% 125mW	MCHP03W8J0101T5E
Resistor, 120R, 0603 5% 125mW	MCHP03W8J0121T5E
Resistor, 150R, 0603 5% 125mW	MCHP03W8J0151T5E
Resistor, 180R, 0603 5% 125mW	MCHP03W8J0181T5E
Resistor, 220R, 0603 5% 125mW	MCHP03W8J0221T5E
Resistor, 270R, 0603 5% 125mW	MCHP03W8J0271T5E
Resistor, 330R, 0603 5% 125mW	MCHP03W8J0331T5E
Resistor, 390R, 0603 5% 125mW	MCHP03W8J0391T5E
Resistor, 470R, 0603 5% 125mW	MCHP03W8J0471T5E
Resistor, 560R, 0603 5% 125mW	MCHP03W8J0561T5E
Resistor, 680R, 0603 5% 125mW	MCHP03W8J0681T5E
Resistor, 820R, 0603 5% 125mW	MCHP03W8J0821T5E
Resistor, 1K, 0603 5% 125mW	MCHP03W8J0102T5E
Resistor, 1K2, 0603 5% 125mW	MCHP03W8J0122T5E

Description	Part Number
Resistor, 1K5, 0603 5% 125mW	MCHP03W8J0152T5E
Resistor, 1K8, 0603 5% 125mW	MCHP03W8J0182T5E
Resistor, 2K2, 0603 5% 125mW	MCHP03W8J0222T5E
Resistor, 2K7, 0603 5% 125mW	MCHP03W8J0272T5E
Resistor, 3K3, 0603 5% 125mW	MCHP03W8J0332T5E
Resistor, 3K9, 0603 5% 125mW	MCHP03W8J0392T5E
Resistor, 4.7K, 0603 5% 125mW	MCHP03W8J0472T5E
Resistor, 5K6, 0603 5% 125mW	MCHP03W8J0562T5E
Resistor, 6K8, 0603 5% 125mW	MCHP03W8J0682T5E
Resistor, 8K2, 0603 5% 125mW	MCHP03W8J0822T5E
Resistor, 10K, 0603 5% 125mW	MCHP03W8J0103T5E
Resistor, 12K, 0603 5% 125mW	MCHP03W8J0123T5E
Resistor, 15K, 0603 5% 125mW	MCHP03W8J0153T5E
Resistor, 18K, 0603 5% 125mW	MCHP03W8J0183T5E
Resistor, 22K, 0603 5% 125mW	MCHP03W8J0223T5E
Resistor, 27K, 0603 5% 125mW	MCHP03W8J0273T5E
Resistor, 33K, 0603 5% 125mW	MCHP03W8J0333T5E
Resistor, 39K, 0603 5% 125mW	MCHP03W8J0393T5E
Resistor, 47K, 0603 5% 125mW	MCHP03W8J0473T5E
Resistor, 56K, 0603 5% 125mW	MCHP03W8J0563T5E
Resistor, 68K, 0603 5% 125mW	MCHP03W8J0683T5E
Resistor, 82K, 0603 5% 125mW	MCHP03W8J0823T5E
Resistor, 100K, 0603 5% 125mW	MCHP03W8J0104T5E
Resistor, 120K, 0603 5% 125mW	MCHP03W8J0124T5E
Resistor, 150K, 0603 5% 125mW	MCHP03W8J0154T5E
Resistor, 180K, 0603 5% 125mW	MCHP03W8J0184T5E
Resistor, 220K, 0603 5% 125mW	MCHP03W8J0224T5E
Resistor, 270K, 0603 5% 125mW	MCHP03W8J0274T5E
Resistor, 330K, 0603 5% 125mW	MCHP03W8J0334T5E
Resistor, 390K, 0603 5% 125mW	MCHP03W8J0394T5E
Resistor, 470K, 0603 5% 125mW	MCHP03W8J0474T5E
Resistor, 560K, 0603 5% 125mW	MCHP03W8J0564T5E
Resistor, 680K, 0603 5% 125mW	MCHP03W8J0684T5E

# High Power Thick Film Resistor 0603



Description	Part Number
Resistor, 820K, 0603 5% 125mW	MCHP03W8J0824T5E
Resistor, 1M, 0603 5% 125mW	MCHP03W8J0105T5E
Resistor, 1M2, 0603 5% 125mW	MCHP03W8J0125T5E
Resistor, 1M5, 0603 5% 125mW	MCHP03W8J0155T5E
Resistor, 1M8, 0603 5% 125mW	MCHP03W8J0185T5E
Resistor, 2M2, 0603 5% 125mW	MCHP03W8J0225T5E
Resistor, 2M7, 0603 5% 125mW	MCHP03W8J0275T5E
Resistor, 3M3, 0603 5% 125mW	MCHP03W8J0335T5E
Resistor, 3M9, 0603 5% 125mW	MCHP03W8J0395T5E
Resistor, 4M7, 0603 5% 125mW	MCHP03W8J0475T5E
Resistor, 5M6, 0603 5% 125mW	MCHP03W8J0565T5E
Resistor, 6M8, 0603 5% 125mW	MCHP03W8J0685T5E
Resistor, 8M2, 0603 5% 125mW	MCHP03W8J0825T5E
Resistor, 10M, 0603 5% 125mW	MCHP03W8J0106T5E

**Important Notice** : This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp is the registered trademark of the Group. © Premier Farnell plc 2012.

[www.element14.com](http://www.element14.com)  
[www.farnell.com](http://www.farnell.com)  
[www.newark.com](http://www.newark.com)

