


---

Item no.: 2092-1326  
Product description: 6 POLE PIN SPACING 5 MM / 0.197 IN

---

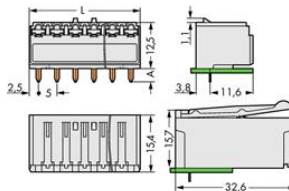

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Color	light gray
pole count	6
Height	13.6 mm
Height	0.535 in
Width	30 mm
Width	1.181 in
Depth	15.4 mm
Depth	0.606 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Material group	I

Customs Tariff No.

85366990

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected