
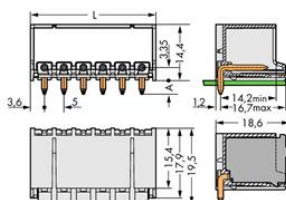


Item no.: 2092-1428
 Product description: 8 POLE PIN SPACING 5 MM / 0.197 IN

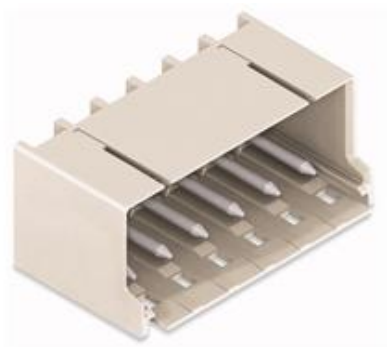

Produkt kann von Bild abweichen / product may differ

RoHS compliant

| | |
|------------------------------|------------|
| Color | light gray |
| pole count | 8 |
| Height | 14.4 mm |
| Height | 0.567 in |
| Width | 42.2 mm |
| Width | 1.661 in |
| Depth | 19.5 mm |
| Depth | 0.768 in |
| Pin spacing from | 5 mm |
| Pin spacing from | 0.197 in |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |
| Measured shock voltage | 4 kV |
| Current intensity EN | 16 A |
| Pollution degree | 2 |
| Measured voltage EN | 630 V |
| Measured shock voltage | 4 kV |
| Current intensity EN | 16 A |
| Solder pin width, diam. [mm] | 1.4 mm |

Material group
Customs Tariff No.

I
85366990

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected