
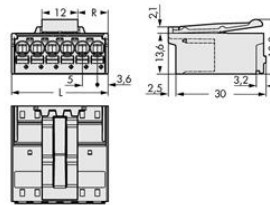


Item no.: 2092-1526/002-000
 Product description: MALE CONNECTOR 6 POLE PIN SPACING 5 MM / 0.197 IN

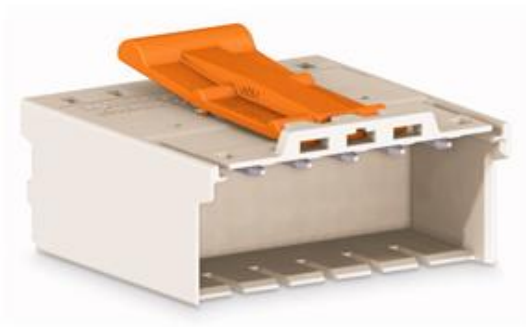

Produkt kann von Bild abweichen / product may differ

RoHS compliant

| | |
|--------------------------|------------|
| Color | light gray |
| No. of connection Points | 6 |
| No. of potentials | 6 |
| pole count | 6 |
| Height | 18.2 mm |
| Height | 0.717 in |
| Width | 32.2 mm |
| Width | 1.268 in |
| Depth | 32.6 mm |
| Depth | 1.283 in |
| Pin spacing from | 5 mm |
| Pin spacing from | 0.197 in |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |
| Measured shock voltage | 4 kV |
| Current intensity EN | 16 A |
| Pollution degree | 2 |
| Measured voltage EN | 630 V |
| Measured shock voltage | 4 kV |

Current intensity EN
Connection method
Cross section [mm²]

16 A
CAGE CLAMP®S Connection
0.2 - 2.5 mm²



| | |
|----------------------------------|----------------------------|
| Wiring method | solid |
| Cross section [mm ²] | 0.2 - 2.5 mm ² |
| Cross section [mm ²] | 0.25 - 1.5 mm ² |
| Cross section [mm ²] | 0.25 - 2.5 mm ² |
| Cross section [AWG] | 24 - 12 AWG |
| Strip length from | 9 mm |
| Strip length to | 10 mm |
| Material group | I |
| Customs Tariff No. | 85366990 |

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected