
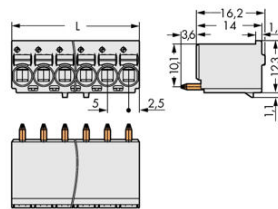


Item no.: 2092-1175  
 Product description: 5 POLE PIN SPACING 5 MM / 0.197 IN

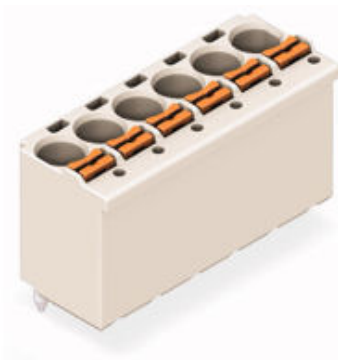

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	light gray
No. of connection Points	5
No. of potentials	5
pole count	5
Height	16.2 mm
Height	0.638 in
Width	25 mm
Width	0.984 in
Depth	13.4 mm
Depth	0.528 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV

Current intensity EN  
Connection method  
Cross section [mm<sup>2</sup>]

16 A  
CAGE CLAMP®S Connection  
0.2 - 2.5 mm<sup>2</sup>



Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.2 - 2.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 2.5 mm <sup>2</sup>
Cross section [AWG]	24 - 12 AWG
Strip length from	9 mm
Strip length to	10 mm
Solder pin width, diam. [mm]	1.4 mm
Material group	I
Customs Tariff No.	85366990

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected