


Item no.: 2092-1382  
 Product description: 12 POLE PIN SPACING 5 MM / 0.197 IN

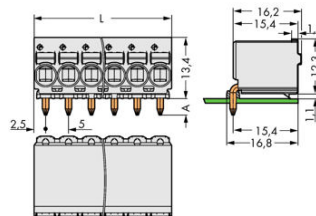

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	light gray
No. of connection Points	12
No. of potentials	12
pole count	12
Height	13.4 mm
Height	0.528 in
Width	60 mm
Width	2.362 in
Depth	15.4 mm
Depth	0.606 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV

Current intensity EN  
Connection method  
Cross section [mm<sup>2</sup>]

16 A  
CAGE CLAMP®S Connection  
0.2 - 2.5 mm<sup>2</sup>



Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.2 - 2.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 2.5 mm <sup>2</sup>
Cross section [AWG]	24 - 12 AWG
Strip length from	9 mm
Strip length to	10 mm
Solder pin width, diam. [mm]	1.4 mm
Material group	I
Customs Tariff No.	85366990

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected