


| | | |
|--------------------------------------|---|--|
| Gripping plates, pluggable | Gripping plates with sliding connector release, pluggable | |
|--------------------------------------|---|--|

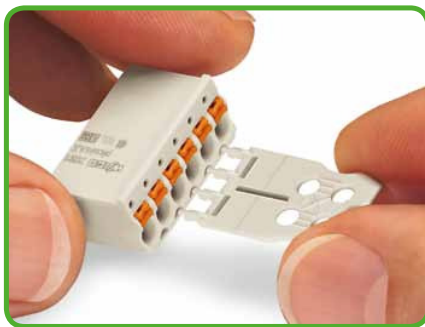

| Pole No. | Item No. | Pack. Unit | Pole No. | Item No. | Pack. Unit |
|--------------------------------------|------------------|--------------|---|--------------------------|--------------|
| Gripping plate, light gray | | | Gripping plate with sliding connector release, light gray | | |
| Pin spacing: 3.5 mm | | | Pin spacing: 3.5 mm | | |
| 2 | 2091-1600 | 100 (4 x 25) | 2 | 2091-1600/002-000 | 100 (4 x 25) |
| 3- 4 | 2091-1601 | 100 (4 x 25) | 3- 4 | 2091-1601/002-000 | 100 (4 x 25) |
| 5- 8 | 2091-1602 | 100 (4 x 25) | 5- 8 | 2091-1602/002-000 | 100 (4 x 25) |
| 9-12 | 2091-1603 | 100 (4 x 25) | 9-12 | 2091-1603/002-000 | 100 (4 x 25) |
| Pin spacing: 5 mm | | | Pin spacing: 5 mm | | |
| 2 | 2092-1600 | 100 (4 x 25) | 2 | 2092-1600/002-000 | 100 (4 x 25) |
| 3- 4 | 2092-1601 | 100 (4 x 25) | 3- 4 | 2092-1601/002-000 | 100 (4 x 25) |
| 5- 8 | 2092-1602 | 100 (4 x 25) | 5- 8 | 2092-1602/002-000 | 100 (4 x 25) |
| 9-12 | 2092-1603 | 100 (4 x 25) | 9-12 | 2092-1603/002-000 | 100 (4 x 25) |
| Pin spacing: 7.5 mm | | | Pin spacing: 7.5 mm | | |
| 2 | 2092-3600 | 100 (4 x 25) | 2 | 2092-3600/002-000 | 100 (4 x 25) |
| 3 | 2092-3601 | 100 (4 x 25) | 3 | 2092-3601/002-000 | 100 (4 x 25) |
| 4- 5 | 2092-3602 | 100 (4 x 25) | 4- 5 | 2092-3602/002-000 | 100 (4 x 25) |



Gripping plates are suitable for factory and in-the-field assembly.