

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [34969-0140](#)  
**Status:** **Active**  
**Overview:** [Stac64™ Single, Multi-Pocket and Hybrid Header System](#)  
**Description:** 2.54mm Pitch Stac64™ Hybrid Receptacle Assembly, 14 Circuit, Black, Polarization A

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-34969-100 \(PDF\)](#)

**General**

Product Family	Crimp Housings
Series	<a href="#">34969</a>
Application	Power, Signal, Wire-to-Board
Comments	Current is dependent on connector size, ambient temperature, blade size and related factors. 2.80mm – 30.0A; 0.64mm - 6.0A. . Polarization A
Overview	<a href="#">Stac64™ Single, Multi-Pocket and Hybrid Header System</a>
Product Name	Stac64™
UPC	887191311913

**Physical**

Circuits (maximum)	14
Circuits Detail	21 x 0.64 and 4 x 2.8
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	No
Material - Resin	Modified Polystyrene
Net Weight	7.690/g
Number of Rows	2
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Ports	1
Stackable	No
Temperature Range - Operating	-40°C to +105°C


**Electrical**

Current - Maximum per Contact	30A, 6A
-------------------------------	---------

**Material Info**

**Reference - Drawing Numbers**

Product Specification	PS-34969-100
Sales Drawing	SD-34969-010

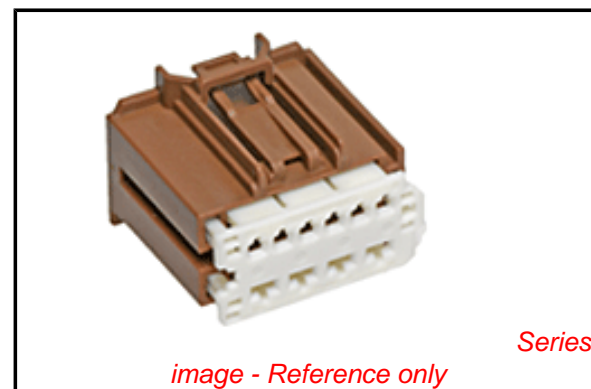

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC Contains SVHC: No**  
**Low-Halogen Status Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[34969Series](#)

**Mates With**

[34729 Stac64™ Receptacle, 31372 Stac64™ Hybrid Hybrid Receptacle Assembly](#)