

## G80-3000



Models may vary from the image shown

### Accurate and reliable even after years of service

The timeless keyboard for high-volume data input and for the most demanding requirements. Durable, reliable and sure switching action. Proven millions of times over. The G80-3000 standard PC keyboard is based on the reliable MX technology with Gold Crosspoint contacts.

### Key benefits

- Individual keys with Gold Crosspoint contacts (MX technology)
- Codeset 3 support (PS/2 connection only) e.g. for Unix computers
- Perfect key feeling
- High-quality keyboard for outstanding writing performance, fulfilling even the highest demands
- Extremely high service life of individual keys
- Three different types of confirmation: linear, soft or click pressure point
- Compatible for PCs and Macs via USB connection
- incl. adapter for PS/2 interface

### Technical Data:

#### Layout (country or language):

Product dependant, see table "Models"

#### Housing colour:

Product dependant, see table "Models"

#### Key colour:

Product dependant, see table "Models"

#### Weight (product):

935 g

#### Total weight (with packaging):

1150 g

#### Cable Length:

approx. 1.75 m

#### Storage Temperature:

-20°C to 60°C

#### Operating Temperature:

0°C to 50°C

#### Current Consumption:

typ. 15 mA

#### Interface:

- USB (PS/2 via adapter)

#### Product approvals:

- cURus 
- VDE GS 
- c-tick 
- VCCI 
- CE 
- FCC 
- BSMI 

#### System requirements:

- USB or PS/2 connection

#### Delivery Volume:

- G80-3000
- Printed instructions
- Adapter (USB socket on PS/2 plug)

#### Dimensions (product):

approx. 470 x 195 x 44 mm

#### Packaging dimensions:

approx. 500 x 255 x 50 mm

#### Reliability:

- MTBF > 80,000 hours
- MCBF > 10 bill. operations

#### Keyboard:

- Key technology: MX
- Service life, standard key: > 50 million key operations
- Operation characteristics: Product dependant, see table "Models"
- Inscription technology: Laser
- Inscription layout: Standard
- Number of Keys: Product dependant, see table "Models"

#### Packaging Unit:

- Number of products in the master package: 45
- Number of master packages per pallet: 2

#### Warranty:

2 years

Errors, technical changes and delivery possibilities excepted. Technical information refers only to the specifications of the products. Features may differ from the information provided.

## Models:

(possible country/layout versions, others available on request)

	Product name	Order number	EAN code	Layout (country or language)	Housing colour	Key colour	Operation characteristics <sup>1</sup>	Number of Keys
1	G80-3000	G80-3000LPCBE-0	4025112066948	Belgium	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
2	G80-3000	G80-3000LPCCH-0	4025112058523	Switzerland	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
3	G80-3000	G80-3000LPCDE-0	4025112058530	Germany	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
4	G80-3000	G80-3000LPCDE-2	4025112058547	Germany	black	black	BLACK SWITCH Linear (60 cN)	105
5	G80-3000	G80-3000LPCDK-0	4025112058554	Denmark	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
6	G80-3000	G80-3000LPCDK-2	4025112069543	Denmark	black	black	BLACK SWITCH Linear (60 cN)	105
7	G80-3000	G80-3000LPCES-0	4025112058561	Spain	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
8	G80-3000	G80-3000LPCES-2	4025112058578	Spain	black	black	BLACK SWITCH Linear (60 cN)	105
9	G80-3000	G80-3000LPCEU-0	4025112058585	US English with EURO symbol	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
10	G80-3000	G80-3000LPCEU-2	4025112061073	US English with EURO symbol	black	black	BLACK SWITCH Linear (60 cN)	104
11	G80-3000	G80-3000LPCFR-0	4025112058592	France	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
12	G80-3000	G80-3000LPCGB-0	4025112058608	UK	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
13	G80-3000	G80-3000LPCGB-2	4025112061646	UK	black	black	BLACK SWITCH Linear (60 cN)	105
14	G80-3000	G80-3000LPCIT-0	4025112061714	Italy	light grey	light grey	BLACK SWITCH Linear (60 cN)	105


	Product name	Order number	EAN code	Layout (country or language)	Housing colour	Key colour	Operation characteristics <sup>1</sup>	Number of Keys
15	G80-3000	G80-3000LPCIT-2	4025112075636	Italy	black	black	BLACK SWITCH Linear (60 cN)	105
16	G80-3000	G80-3000LPCJK-0	4025112076107	Japan (Katakana)	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
17	G80-3000	G80-3000LPCKO-0	4025112076114	English (US) / Korean	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
18	G80-3000	G80-3000LPCNL-0	4025112078286	Netherlands	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
19	G80-3000	G80-3000LPCNO-0	4025112061486	Norway	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
20	G80-3000	G80-3000LPCNO-2	4025112061066	Norway	black	black	BLACK SWITCH Linear (60 cN)	105
21	G80-3000	G80-3000LPCPO-0	4025112076138	Portugal	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
22	G80-3000	G80-3000LPCRB-0	4025112059230	English (US) / Cyrillic	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
23	G80-3000	G80-3000LPCRB-2	4025112059247	English (US) / Cyrillic	black	black	BLACK SWITCH Linear (60 cN)	104
24	G80-3000	G80-3000LPCRC-0	4025112076145	English (US) / Chinese	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
25	G80-3000	G80-3000LPCRC-2	4025112068805	English (US) / Chinese	black	black	BLACK SWITCH Linear (60 cN)	104
26	G80-3000	G80-3000LPCSF-0	4025112077050	Sweden / Finland	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
27	G80-3000	G80-3000LPCSF-2	4025112063442	Sweden / Finland	black	black	BLACK SWITCH Linear (60 cN)	105
28	G80-3000	G80-3000LQCCH-0	4025112058622	Switzerland	light grey	light grey	CLEAR SWITCH Pressure point (65cN)	105
29	G80-3000	G80-3000LQCDE-0	4025112058639	Germany	light grey	light grey	CLEAR SWITCH Pressure point (65cN)	105

Product name	Order number	EAN code	Layout (country or language)	Housing colour	Key colour	Operation characteristics <sup>1</sup>	Number of Keys	
30	G80-3000	G80-3000LQCDE-2	4025112063374	Germany	black	black	CLEAR SWITCH Pressure point (65cN)	105
31	G80-3000	G80-3000LQCEU-0	4025112058646	US English with EURO symbol	light grey	light grey	CLEAR SWITCH Pressure point (65cN)	104
32	G80-3000	G80-3000LQCEU-2	4025112067013	US English with EURO symbol	black	black	CLEAR SWITCH Pressure point (65cN)	104
33	G80-3000	G80-3000LQCRB-2	4025112058653	English (US) / Cyrillic	black	black	CLEAR SWITCH Pressure point (65cN)	104
34	G80-3000	G80-3000LSCDE-0	4025112058660	Germany	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	105
35	G80-3000	G80-3000LSCDE-2	4025112063381	Germany	black	black	BLUE SWITCH Click pressure point (60cN)	105
36	G80-3000	G80-3000LSCEU-0	4025112058677	US English with EURO symbol	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	104
37	G80-3000	G80-3000LSCEU-2	4025112067020	US English with EURO symbol	black	black	BLUE SWITCH Click pressure point (60cN)	104
38	G80-3000	G80-3000LSCFR-0	4025112061820	France	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	105
39	G80-3000	G80-3000LSCGB-0	4025112058684	UK	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	105
40	G80-3000	G80-3000LSCGB-2	4025112066290	UK	black	black	BLUE SWITCH Click pressure point (60cN)	105
41	G80-3000	G80-3000LSCGR-0	4025112068249	Greece	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	105
42	G80-3000	G80-3000LSCIT-2	4025112075629	Italy	black	black	BLUE SWITCH Click pressure point (60cN)	105
43	G80-3000	G80-3000LSCRB-2	4025112058714	English (US) / Cyrillic	black	black	BLUE SWITCH Click pressure point (60cN)	104
44	G80-3000	G80-3000LSCRC-0	4025112058691	English (US) / Chinese	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	104


Product name	Order number	EAN code	Layout (country or language)	Housing colour	Key colour	Operation characteristics <sup>1</sup>	Number of Keys	
45	G80-3000	G80-3000LSCRC-2	4025112058707	English (US) / Chinese	black	black	BLUE SWITCH Click pressure point (60cN)	104
46	G80-3000	G80-3000LSCSL-0	4025112065057	Slovenia	light grey	light grey	BLUE SWITCH Click pressure point (60cN)	105

## 1 Operation characteristics:

- BLACK SWITCH Linear (60 cN)

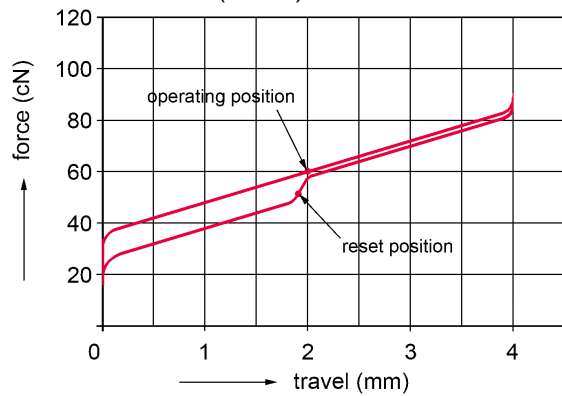

- BLUE SWITCH Click pressure point (60cN)

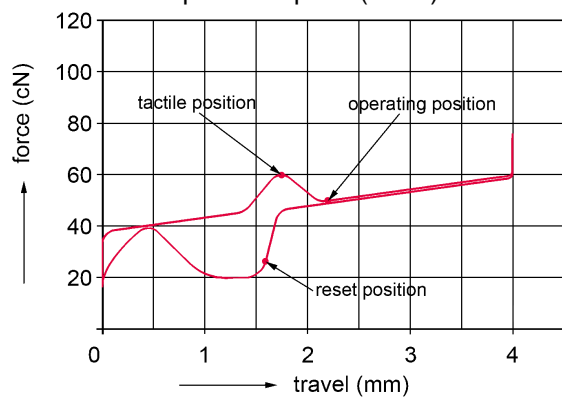

- CLEAR SWITCH Pressure point (65cN)

