



92.13



P.C.B. SOCKET (flange mount with M3 screws)

TYPE 92.13 for relays types 62.32 - 62.33

Accessories: retaining clip **TYPE 092.54**

SOLDER CONNECTIONS SOCKET

TYPE 92.33 for relays types 62.32 - 62.33

Accessories: retaining clip **TYPE 092.54**

CHARACTERISTICS

- LOAD: 32 A 250 V (10 A max for each contact circuit)
- INSULATION RESISTANCE: $\geq 10^3$ M Ω
- DIELECTRIC STRENGTH: ≥ 2.5 kV AC
- BODY MATERIAL: self-extinguishing PPEm (V1)
- CONNECTIONS: Cu Zn 33 tin plated



92.43.1



**SCREW TERMINAL SOCKET
(panel or DIN rail 46277 mount)**


TYPE 92.43.1 for relays types 62.32 - 62.33

Accessories: retaining clip **TYPE 092.53**


IP 20 protective cover **TYPE 092.55**

CHARACTERISTICS

- LOAD: 16 A 250 V
- INSULATION RESISTANCE: $\geq 10^3$ M Ω
- DIELECTRIC STRENGTH: ≥ 2.5 kV AC
- BODY MATERIAL: self-extinguishing PPEm (V1)
- CONNECTIONS: Cu Zn 33 nickel plated
- Non removable pozidrive slotted terminal screws.

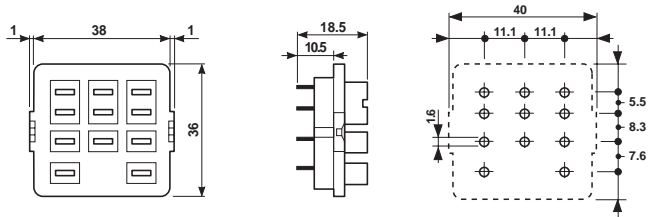

92.13

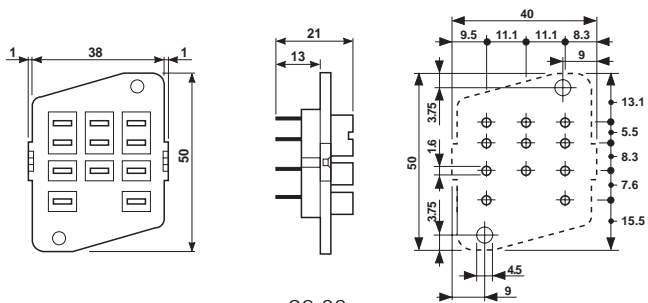

92.33

