

- Replacement for a 34W incandescent bulb
- Up to 84% energy saving
- Lifetime of 30,000 hrs
- An energy efficient LED solution for general lighting.



Order Code 52129

General Data

Lamp Socket B22
Design Frosted

Geometric Data

Length (mm) 110
Diameter (mm) 60
Weight (g) 155

Electric Data

Wattage (W) 5.5
Wattage Equivalent (W) 34
Voltage (V) 220-240
Power Factor ≥ 0.40
Operating Frequency (Hz) 50-60

Photometric Data


Luminous Flux (lm) 380
CRI ≥ 80
CCT (K) 3000
Luminous Intensity (cd) 80
Beam Angle (°) 130


Lifespan

Lifetime (hrs) 30,000
Switching Cycle 20,000

Dimmability No

Energy Efficiency Class A+

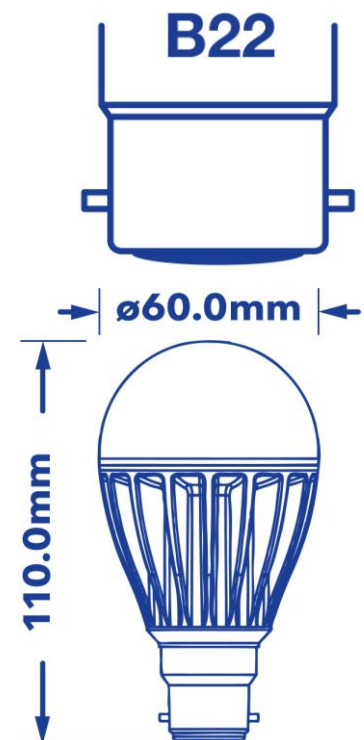

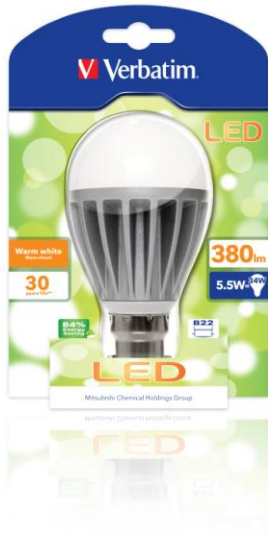

Order Code 52129
Product Description LED Classic A B22 5.5W 3000K WW 380LM 130DEG

Technical Packaging Details

Barcode	023942521297
EAN 128	(02)00023942521297(37)04(91)204
EAN 14	50023942521292
Pack Dimensions (HxWxL)	178mm x 118mm x 61mm
Pack Weight	TBC
Carton Qty (Shipping Unit)	4
Carton Dimensions (HxWxL)	195 mm x 144 mm x 253 mm
Cartons/Pallet	80
Layers/Pallet	4
Units/Pallet	320

Photometric Diagram

52129

