

## Product details

---

Article: 19411235M



Indicator, M16, prominent bezel, black chrome, 230V AC, green

### Description

Description: Indicator, M16, prominent bezel, black chrome, 230V AC, green

UL listed: Yes

 VDE certified : Yes

### Optical features

Colour: green

Dominant Wavelength: 525 nm

Luminous intensity at DC current: 255 mcd

Bezel color: black chrome

Lens color: green

### Electrical features

Voltage: 230 V

Voltage type: AC

Rectifier: Half wave

Voltage tolerance: 10 %

AC current: 3 mA

Protection: IP67

### Mechanical features

Number of Chips: 1

Indicator type: standard

Mounting type: With bezel

Bezel typ: Prominent bezel

Bezel material: Metal

Bezel size: M16

Lens typ: Flat

Lens size: 10 mm

Lens surface: diffused

Connector type: Tab terminals 2

Number of Connectors: 2

### Thermal features

Operating temperature: -25...+60 °C


Storage temperature: -25...+60 °C

## Divers

Connectors for lamp test: No

Comment: With protection tube

## Gallery

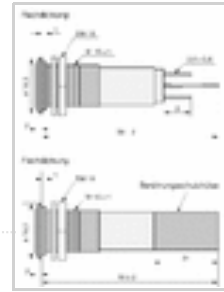

**UniStarLEDs - SMD LED Lamps**  
Incandescent lamp replacement  
T5.5 - BA9s - E10 - E14