

MobiNote Mini



MobiNote Mini

New Design

- Wireless personal handy speaker
- Portable : Use the speaker anywhere , many applications
- Bluetooth : Wireless music / hands-free speaker phone
- Great sound for watching online movies
- Built-In lithium battery : USB charge for up to 7 hours of music







step1

Open the interface dust cover and charged for 2 hours by mini USB and it can music play 5-7 hours at 70% volume..




step2

Open the interface dust cover and turn on the power switch.



step3

Turn on Bluetooth function of your device and search "Orange" to connect.

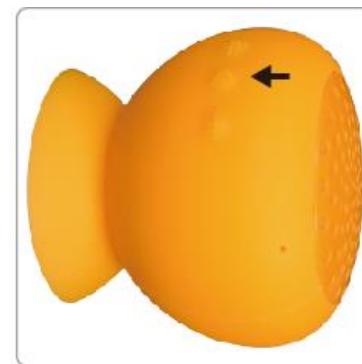


step4

Answer/ hang up the phone call under Bluetooth mode; Long-pressing the key to ring back the last call.




step5

Press the button "+" to enlarge the volume.

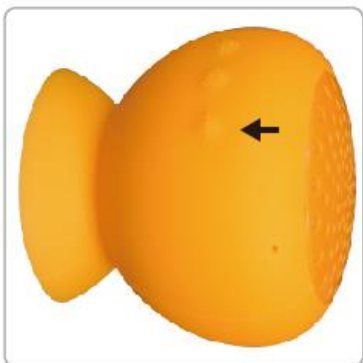

step6

Press the button "-" to decrease the volume.

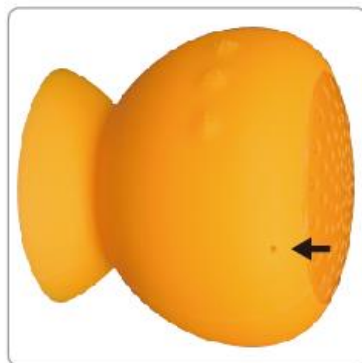

step7

Serve as microphone during hands-free call.



step8

Suction cup: Capable of sucking on any smooth surface (glass, glossy wall, ceramic, etc..)

MobiNote Mini - Locations

■ Smartphone




■ Tablet



■ Bathroom



■ Bedroom

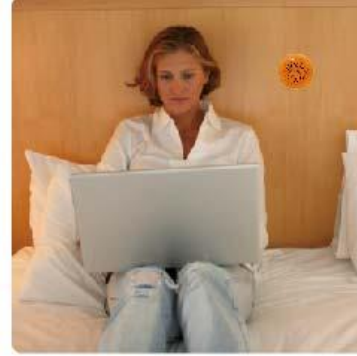

■ Kitchen



■ Conference call



■ Car



■ Business trip



■ Vacation



■ Office





MobiNote Mini



Applications:

Music, video, speakerphone

Age Groups:

anyone · Teenagers, travelers, backpackers

Locations:

Bathroom, kitchen, tablet, smart-phone, car, office etc..

Competitors:

Jawbone, Logitech



Colors Samples



Specification

Bluetooth Wireless Speaker

Feature	<ul style="list-style-type: none">• Suitable for kids, music lovers and gift market• Special vacuum suction cup design, sticks on any flat surface, including desk, wall, window etc.• Stick on back of iPad, iPhone or SmartPhone to use as a stand• Bluetooth 3.0, connects to any Bluetooth device easily• Built-in Microphone, supports phone conversation
Size	Φ62*H59mm
Material & Colour Options	
Unit	Silicon cover + ABS plastic
Color	Red/Orange / Pink/Yellow/Green/Blue/Purple/Dark Grey/White

Specification

Bluetooth	Bluetooth 3.0, CSR solution, high quality audio
Driver	40mm, 4Ω 3W
Built-in Battery	450mAH, Li-ion battery
Voltage	DC 3.7V
Function Key	Volume +/-, Dial up/Hang down
Output power	3W
Built-in Microphone	Yes
LED Indicator	1.Charge full: No LED flashing 2.Charging: Red LED on 3.Bluetooth paring: Red and Blue LED flashing 4.Bluetooth connected: Blue LED slowly flashing
USB cable	1PC
Certificates	CE, FCC, RoHS, Bluetooth BQB