

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35728-0201](#)
Status: **Active**
Description: 2.00mm Diameter Socket Terminal, Brass, 0.25mm Thickness, Wire Range 14-20 AWG (2.00-0.52mm²), Pre-Tin Plated

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-35728-001 \(PDF\)](#)
[Product Specification PS-35141-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	35728
Application	Power
Crimp Quality Equipment	Yes
Product Name	N/A
UPC	800754939959

Physical

Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.306/g
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.90-3.40mm
Wire Size AWG	14, 16, 18, 20
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35728-001
Product Specification	PS-35141-001
Sales Drawing	SD-35728-0201

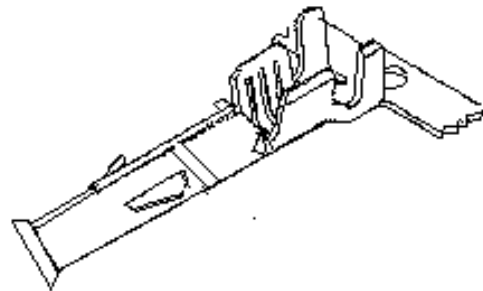


image - Reference only

Series

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[35728Series](#)

Mates With

2.00mm Diameter Pin|[35727-0201](#)

Use With

[35143](#) , [35144](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Crimp Hand Tool	0638252900
Mini-Mac™	0638923000
Applicator	