


P-Mounts The one-hole fixing solution for heavy duty applications

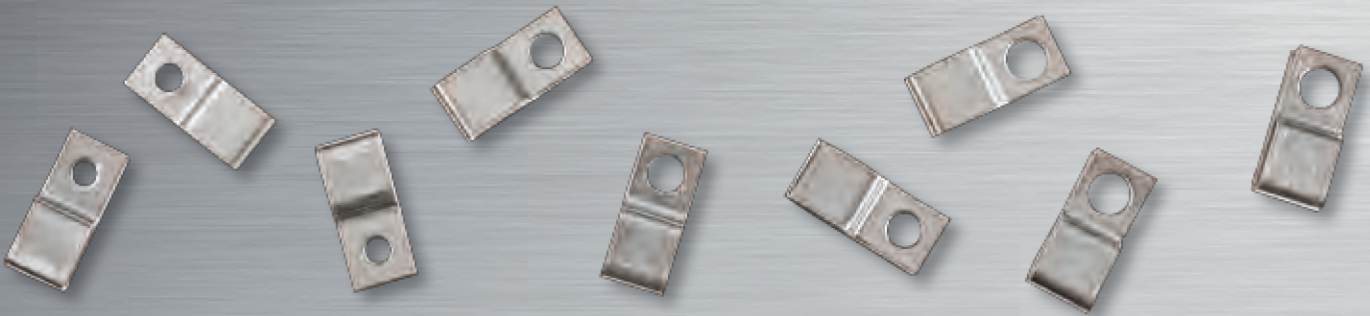

P-Mounts.

Stainless Steel P-Mounts

Stainless steel P-Mounts are ideal for use with our range of stainless steel ties. Designed as a one hole fixing solution, the mount is made of a high performance 316 grade stainless steel.

The range consists of three different hole sizes that are suitable for screw diameters of 4 mm, 5 mm and 6 mm. With a slot width of 10 mm, the P-Mounts can be used in combination with our range of MBT, MLT and MAT products. With its heavy duty design, the stainless steel P-Mount provides a sustainable and durable fixing solution.

Note: It is recommended that stainless steel screws/bolts are used to install the P-Mounts to prevent potential corrosion.

Application

- Used in the most arduous of environments
- Where additional security, strength and fire resistance of a metal fixing is required (hazardous environments)
- Used for fixing cables, tubing, conduits and pipes

Material	Stainless Steel Type SS316
Operating Temperature	-80 °C to +538 °C
Flammability	Non burning



Article-No.	Type	Length (L)	Width (W)	Height (H)	Hole Diameter	Screw Diameter	Cable Tie Width Max.	Material
151-00837	SSPC4	23.0	10.2	4.5	4.2	4.0	10.0	SS316
151-00838	SSPC5	23.0	10.2	4.5	5.3	5.0	10.0	SS316
151-00839	SSPC6	23.0	10.2	4.5	6.3	6.0	10.0	SS316

All dimensions in mm. Subject to technical changes.