


RJSX03-25-F-X-IP65 (25mm Non-Illuminated Anti-Vandal Switch)



Φ25mm diameter
 Switch Rating: 5A/250VAC
 Contact Configuration: 1NO1NC / 2NO1NC
 Operation Type: Momentary / Latching
 The Front Shape: Flat Head
 The Surface Material: BS/SS/B/BLK
 IP Degree: IP65 IK10

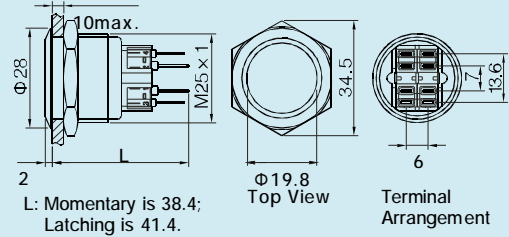

RJSX03-25-F-(BS/SS/B/BLK)-IP65

RJS103 = Single Pole Type 3 Series

RJS203 = Double Pole Type 3 Series

25 = Diameter (in mm)

F = Flat Head

BS/SS/B/BLK = Brushed Steel / Shiny Steel / Brass / Black (Surface Finish)

IP65 = IP Degree, IP 65 Standard

Specification	RJSX03-25-F-X-IP65	
The Front Shape	Flat Head	
Terminal Type	Tag Terminals (2.8 X 0.5mm)	
Switching	ZA (Double Break fast motion changeover contact)	
Max. Switch Rating	5A/250VAC	
Contact Resistance	≤50mΩ	
Insulation Resistance	≥1000MΩ	
Dielectric Intensity	2000VAC	
Operating Temp	-20°C ~ +55°C	
Mechanical Life	1,000,000cycles	
Electrical Life	50,000cycles	
Panel Thickness	1~6mm	
Torque	5~14Nm	
Operation Pressure	About 5.5 - 7N	
Operation Distance	About 2.8mm	
IP Degree	IP65, IK10	
Material	Contact	Silver Alloy
	Button	BS/SS/B/BLK
	Body	BS/SS/B/BLK
	Base	PA
	ROHS	Made to order