

FNL2BU1

HANDS-FREE

- Large spring clip mounts on many surfaces
- Light where you need it without having to hold it



RELIABLE

- Lifetime LED light source
- 10 hours continuous run time (using Energizer® CR2032 Lithium coin cells)



HANDY

- Flexible neck repositions easily
- Slide switch is easy to operate



BRIGHT

- White LED provides 14 lumens
- Features wide-angle LED for full page illumination



Flexibility is the hallmark of the Energizer® LED Clip Light. Useful in many up-close applications, the large extended spring clip mounts securely to books, clipboards and eReaders. The neck bends easily and then holds its position for precision lighting.

A 10-hour run time and lifetime LED lamp keep operating costs low.




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

Product Detail:

Designation:	Energizer LED Clip Light
Model:	FNL2BU1
Color:	Black with Blue trim, White with Black trim
Power Source:	Two CR2032 Lithium Coin Cells
ANSI/NEDA:	5004LC Series
Lamp:	One White LED
Lamp Life (hr):	Lifetime
Lamp Output (lumens):	14
Beam Distance (m):	7
Peak Beam Intensity (cd):	13
Run Time (h:mm):	10
Typical Weight:	38 grams with batteries
Dimensions (mm):	265 x 24

Performance:

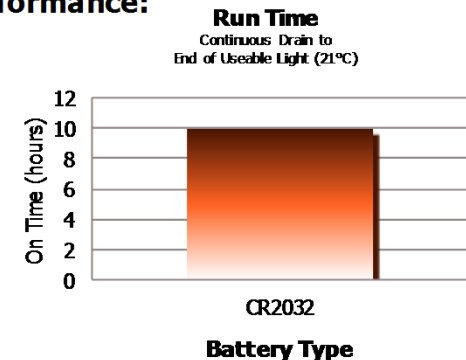

Tested according to ANSI/NEMA FL 1 Standards.

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a warranty
©Energizer / All Rights Reserved