



### Overview

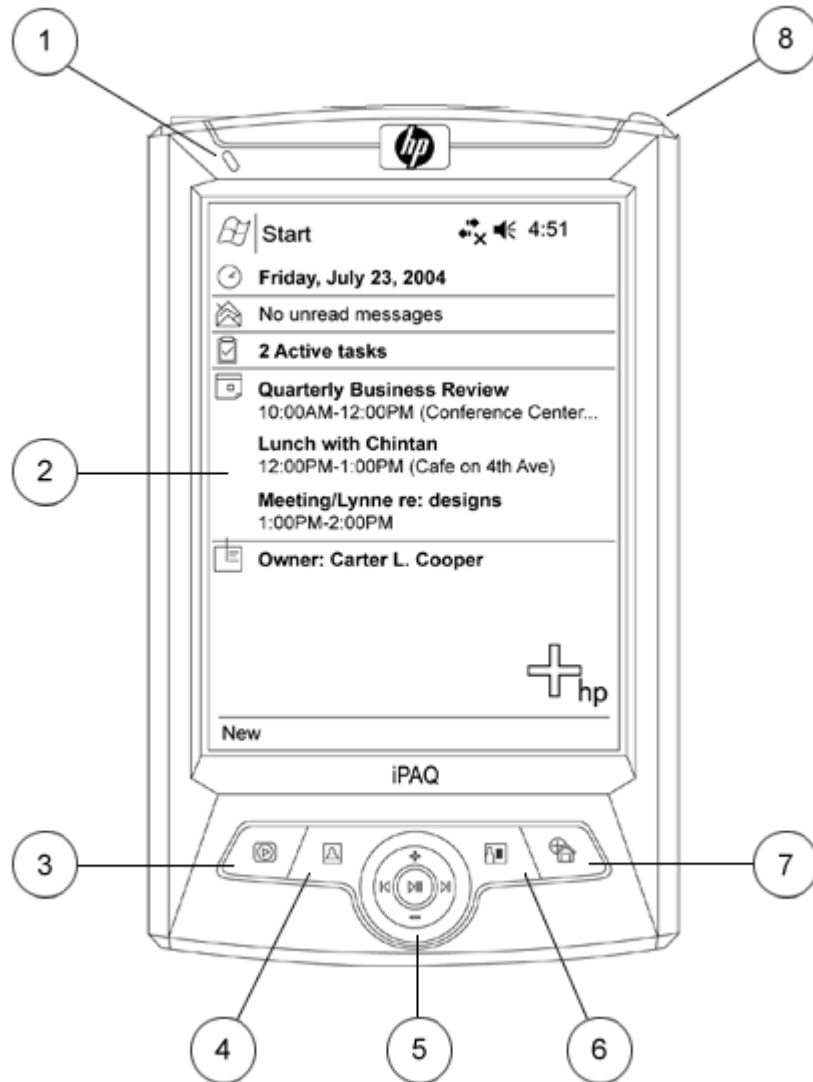

- 1. Charge/Notification LED indicator
- 2. QVGA Color Display
- 3. Calendar Button
- 4. Contacts Button
- 5. 5-Way Navigation Touch Pad
- 6. Messaging Button
- 7. Today Screen Button
- 8. Stylus

### Overview

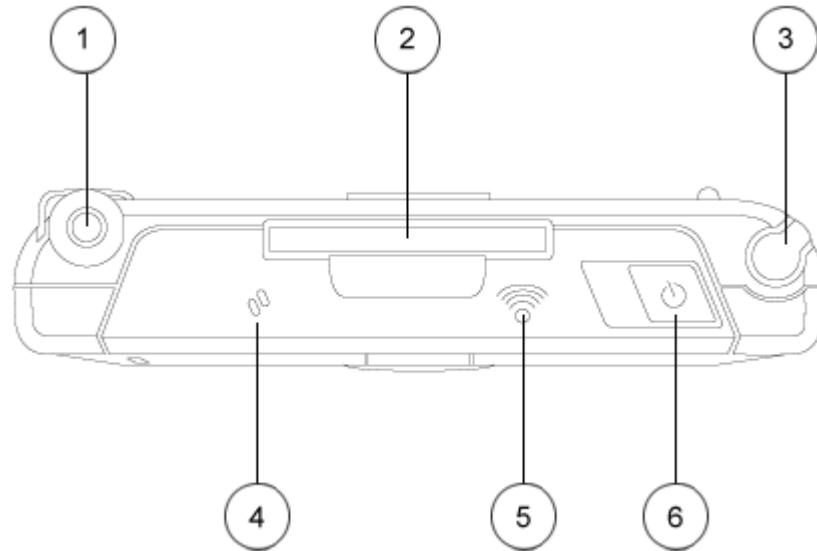

1. 3.5 mm Stereo Headphone Jack
2. SD Slot (SDIO)
3. Stylus
4. Microphone
5. Infrared Beam
6. Power Button

### At A Glance

- Stay productive with Pocket versions of familiar applications like Microsoft® Outlook®, Word and Excel
- Dazzling Transflective QVGA TFT color display, Landscape and Portrait modes
- Microsoft® Windows Mobile™ 2003 Second Edition software for Pocket PC
- Integrated SD expansion slot (SDIO)
- Rechargeable Lithium-Ion battery
- Entertainment while on the go with ability to view photos, play games, music and video
- View Photos with HP Image Zone software

### Standard Features

#### Models

HP iPAQ rz1710 Pocket PC – 32 MB Flash ROM/32 MB SDRAM

FA289A#ABA – US Commercial

---

<b>Processor</b>	203 MHz Samsung S3C2410 processor	
------------------	-----------------------------------	--

---

<b>Memory</b>	<b>User Available Memory</b>	Up to 25 MB user available memory including 10 MB iPAQ File Store on model HP iPAQ rz1710
---------------	------------------------------	---

---

<b>Display</b>	<b>Type</b>	Transflective type QVGA TFT
	<b>Modes</b>	Portrait and Landscape
	<b>Number of Colors</b>	64K color (65,536 colors) 16-bit
	<b>Touch Screen</b>	Yes
	<b>Resolution (W x H)</b>	240 x 320
	<b>Viewable Image Size</b>	3.5 in (89 mm)

---

<b>Hardware Buttons/ Reset Buttons</b>	One power button, one reset button, four shortcut software programmable application buttons, one 5-way navigation button	
--	--	--

---

<b>Stylus</b>	One	
---------------	-----	--

---

<b>Audio</b>	Microphone, speaker, one 3.5 mm headphone jack, MP3 stereo through audio jack	
--------------	---	--

---

<b>Indicators</b>	<b>Charge/Notification LED</b>	Charge and Notify indicators Blinking amber LED – charging Solid amber LED – full charge Blinking green – event notification
	<b>Notification</b>	Sound and message on the display

---

<b>Cradle Interfaces</b>	<b>Connector</b>	1 – 22 pin
--------------------------	------------------	------------

---

<b>Other interfaces</b>	<b>IrDA</b> – Supported (Standard IR) <b>USB</b> – Supported via sync cable <b>Serial</b> – Supported <b>Sync/Data Connector</b> – Full RS 232 support	
-------------------------	---	--

---

### Standard Features

**SD Slot** Support 4-bit SDIO and 4-bit SD/Multimedia Card type memory standard

---

**Power Supply**

**Battery** Internal Rechargeable 1000 mAh Lithium-Ion battery. Estimated usage time of fully charged battery is up to 7 hours. Charging time up to 4 hours.

**AC Power** AC Input: 100~240 Vac, 50/60 Hz, AC Input current: 0.2 Aac max  
Output Voltage: 5Vdc (typical), Output Current: 2A (typical)

**NOTE:** Battery run time varies based on the usage pattern of an individual user and the configuration of the handheld. Use of backlight will significantly decrease battery run time.

---

**AC Adapter**

**Dimensions (H x W x D)** 3 x 1.9 x 1.8 in (76 x 48 x 44 mm - including prongs), (may vary by model)

**Cord Length (approx.)** 6 ft (1.83 m)

**Power Supply Ratings**

Voltage Range	100 to 240 V Switching
Input Current	0.3 Aac
Input Frequency	50 to 60 Hz
Output Voltage	5 VDC
Output Current	2 Amp

---

**System Unit**

**Dimensions (H x W x D)** 4.48 x 2.75 x .53 in (114 x 70 x 13.4 mm)

**Weight** 4.23 oz (120 g)

**Operating Temperature** 32° to 104° F (0° to 40° C)

**Storage Temperature** -4° to 140° F (-20° to 60° C)

**Operating Humidity** 90% RH

**Regulatory Marks**

<b>Electrical</b>	FCC Class B, Canadian ICES-003 Class B, CE
<b>Safety</b>	UL or CSA, NRTL C-UL, NOM

---

**Design Features** 4 programmable application launch buttons – defaults Calendar, Contacts, Messaging and Today buttons. Push and hold application buttons to launch additional programs: Windows Media Player, HP Image Zone, Record; Landscape/Portrait toggle

---

**Operating System** Microsoft® Windows Mobile™ 2003 Second Edition software for Pocket PC – Professional for model HP iPAQ rz1710

Pocket versions of Microsoft software are included (Outlook, Word, Excel and Internet Explorer for Pocket PC)

---

### Standard Features

#### Operating System Applications

Powered by Microsoft® Windows Mobile™ 2003 Second Edition for Pocket PC – Professional, Calendar, Contacts, Tasks, Voice Recorder, Notes, Pocket Word (with Spellchecker), Pocket Excel, Pocket Internet Explorer, Pocket MSN, Windows Media Player 9 (MP3, audio and video streaming), Calculator, Solitaire, Jawbreaker, Messaging (with Spell Checker for email), File Explorer, Infrared Beaming, VPN support (PPTP) Clock, Align Screen, Memory, Volume control. Premium version also includes Microsoft Reader (eBooks), and VPN support (L2TP IPSEC).

#### Additional Software and links

Outlook 2002, Microsoft ActiveSync 3.7.1 (Desktop device synchronization), Links to Microsoft websites for additional downloadable applications (some programs may require purchase of additional desktop software to utilize Pocket PC versions)

#### In-the box

HP iPAQ rz1710 Pocket PC unit, AC adapter, USB sync cable, Stylus, "How do I" guide, HP iPAQ Pocket PC Companion CD and Documentation kit

#### Service and Support

1-year parts and labor in all regions. 90 days technical support for software in most regions. Additional offers may vary by region.

#### HP Exclusive Applications

iPAQ File Store: non-volatile storage in flash ROM  
Experience HP iPAQ: flash demo to show key features in HP iPAQ  
HP Image Zone for Pocket PC: application to view and create slide shows  
HP Task Switch: switch between programs or close open programs  
HP Profiles: set up setting profiles for meeting, outdoor, and other situations  
Utilities: Self Test, Audio, Power Status, Key Lock

#### Companion CD from HP

##### APPLICATIONS

###### Full Versions

Adobe Reader  
Active Sync  
Outlook 2002 Desktop  
Windows Media Player  
Desktop  
Peacemaker (US Retail only)  
Illum Dockware

###### Trial Versions

Audible Player  
List Pro  
WorldMate  
Clear View Player  
Pocket Slides

##### CD LINKS

###### Full Versions

Handango  
Flash Player for Pocket PC  
Microsoft Games  
AvantGo Trial  
Software Choice (EMEA)

###### Trial Versions

Sprite Backup  
Vindigo

##### Additional Documentation

Safety and Comfort Guide on PDF, and User Guide on PDF, How Do I Guide on PDF

### Standard Features

**NOTE:** Programs could vary based on model. Some programs are accessed through CD links to download web sites.

### Options

**NOTE:** Optional accessories are available at additional costs, see <http://www.hp.com/go/ipaqaccessories> for details.

<b>Memory Card</b>	128 MB SD Memory Card	FA135A#AC3
	256 MB SD Memory Card	FA136A#AC3
	512 MB SD Memory Card	FA184A#AC3
	1 GB SD Memory Card	FA283A#AC3
<b>Power</b>	Auto Adapter	FA125A#AC3
	Charger Adapter	FA133A#AC3
	AC Adapters	FA130A#ABA
<b>Synchronization</b>	USB Desktop Cradle/Charger	FA260A#AC3
	AutoSync Cable (USB and Serial)	FA122A#AC3
<b>Other</b>	Stylus Three-pack	FA261A#AC3
	Foldable Keyboard	FA118A#ABA
	Thumb Keyboard (available August 2004)	FA302A#AC3
<b>Performance</b>	SDIO Camera (Photosmart Mobile Camera)	FA185A#ABA
<b>Cases</b>	Custom Cases: To view and place an order: <a href="http://www.ecases.com">http://www.ecases.com</a>	
	Leather Belt Case	FA160A#AC3
	Nylon Slimline Case	FA161A#AC3
	Leather Flip Case	FA349A#AC3

### Options



### HP iPAQ Pocket PC is a Microsoft® Windows® Powered Pocket PC

For more information on HP iPAQ Pocket PC, visit our website at <http://www.hp.com/go/iPAQ>.

©2005 Hewlett-Packard Development Company, L.P.

The information in this document is subject to change without notice.

The only warranties for HP products and services are set forth in the express warranty statements accompanying such products and services. Nothing herein should be construed as constituting an additional warranty. HP shall not be liable for technical or editorial errors or omissions contained herein. Microsoft, Windows, the Windows Logo and ActiveSync are registered trademarks or trademarks of Microsoft Corporation in the United States and/or other countries. Intel is a registered trademark of Intel Corporation in the U.S. and/or other countries.