




high deflection no-snag, fold-under

WITH ADHESIVE MOUNT. For applications requiring low compression force. Designed with a minimum residual stress and highly leveraged spring action. The free end features a fold-under lip which facilitates a low coefficient of friction on most surfaces. Allows a minimum of compressive force to move through the deflection range, resulting in the highest levels of shielding effectiveness with a minimum force.

Extremely high endurance life. Installs easily with standard Very High Bond adhesive.

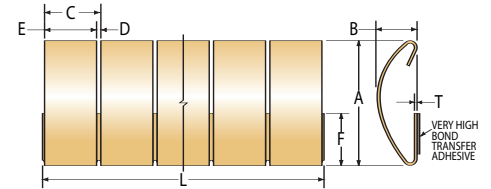

Part Number		A	B	C	D	E	F	T	L	Number of (ref.) Fingers
Bright Copper	Tin Plated									
SG930957CU	SG930957SN	.310 7,9	.120 3,0	.187 4,7	.020 0,5	.168 4,30	.170 4,3	.0027 0,07	15.0 381,0	80
SG960951CU	SG960951SN	.610 15,5	.260 6,4	.375 9,5	.020 0,5	.355 9,02	.250 6,4	.0030 0,08	15.0 381,0	40