



GREENLEE[®]
COMMUNICATIONS
A Textron Company

Tele-Mate[®] Pro Telephone Test Sets

TM-700, TM-700T, TM-700i and TM-700UK



Easy to Use, DSL Compatible, “Smart” Telephone Test Set.

In the evolving world of telecommunications, the **NEW Tele-Mate[®] Pro Telephone Test Set** is designed to help technicians install, service and maintain voice services with ease. Able to tackle the complexities of today's telecommunication lines, the TM-700 is DSL compatible in both Monitor and Talk modes. The TM-700 LCD enhances technician productivity by clearly showing data for polarity, voltage, current and ringing frequencies, whilst simplifying

use of the ten speed dial memories and ten last numbers dialed. Added capabilities such as intercom mode, built in “toner” for pair tracing and DTMF detection & measurement further enhance technician productivity. The TM-700 can be used with the built in loudspeaker or with the headset (included as standard) for easy hands-free operation. The TM-700 aids safe operation with over-voltage and over-current detection.

Features

- LCD for measurements and easy dialing and programming
- Voltage measurement on-hook
- Current measurement off-hook
- Ringing frequency measurement
- Caller ID
- DTMF detection and measurement
- Intercom, allowing "dead-pair" communications
- SmartIntercom™ - between Tele-Mate® Pro units (old or new type) allows "ringing" the far end
- Tone generator function for pair identification
- Luminescent (glow-in-the-dark) keypad
- Can be used safely on a DSL enabled line
- Very High Impedance electronically amplified Monitor for monitoring line without disrupting existing traffic
- Over voltage and over current protection
- Tone and Pulse dialling for versatility on old and new phone lines
- Versatile product, user selectable options allow USA or ETSI telephony setups with individual options also available
- Ten 32 digit last number redial memories
- 10 number speed dial
- Adjustable volume control plus mute
- Pause
- Flash to generate a timed break recall
- Requires just two AA cells, readily available and low cost
- Loudspeaker for listening
- Headset (included) for hands free operation
- RJ11 socket allowing versatile cord options

Specifications

TECHNICAL SPECIFICATIONS

Length:	9.25" (235 mm)
Width:	2.5" (64 mm)
Height:	3.25" (83 mm)


Ordering Information

CAT NO.	UPC NO.	DESCRIPTION	QTY.
TM-700	00984	TM-700 Test Set with ABN "Bed-Of-Nails" Croc Clips & RJ11 (POS)	1
TM-700T	00983	TM-700 Test Set with ABN "Bed-Of-Nails" Croc Clips & RJ11 (Boxed)	1
TM-700i	00977	TM-700 Test Set with Small Croc Clips (Boxed)	1
TM-700UK	00978	TM-700 Test Set with BT Plug (Boxed)	1

NOTE 1: The TM-700i contains standard, small croc clips that do not pierce wiring. ABN style clips are also known as "bed of nails" since they pierce the wiring for testing.

NOTE 2: The TM-700 (POS - point of sale, with full color "oversleeve") replaces the PE830. The PE-830 is discontinued.

DISTRIBUTOR INFORMATION:

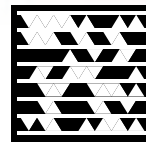

USA
Tel: 800.435.0786
Fax: 800.451.2632

CANADA
Tel: 866.384.8813
Fax: 800.524.2653

INTERNATIONAL
Tel: +1.815.397.7070
Fax: +1.815.397.9247