

## 7W LED PAR20 Reflector

KLED07P20/E27-830 KLED07P20/E27- 865


### Photograph

---



### Product Code Format

---

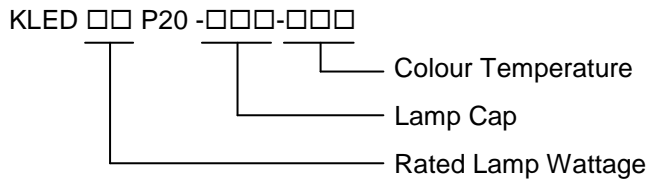

### Features

---


- Save energy up to 90% comparing with halogen lamps.
- Long Life of 30000h, 25 times longer than halogen lamp.
- Popular E27 base and standard shape for direct replacement of E27 lamp.
- Instant start.
- Not dimmable
- No UV output.
- Lamp life may reduce when used in an enclosed fitting.

## Specifications

Rated Lamp Wattage	7W	Peak Candelas	700cd (3000K)
Equ. Wattage	60W		1000cd (6500K)
Input Voltage	220-240V	Ambient Temperature(Ta)	-20°C to 50°C
Line Frequency	50/60Hz	Case Temperature(Tc)	Max. 70°C
Input Current	60mA	LED Chip	Epistar
Quantity of LED(pcs)	5	Length	98mm
Dimmable	No	Diameter	61mm
Base	E27	Packaging Type	Colour Box
Beam Angle	36°	Qty Per Box	1
Rated Life	30000h	Qty Per Carton	50
Colour Temperature	3000K/6500K	Net Weight Per Piece	120g
CRI	76 Ra	Gross Weight Per Carton	7.2 kg
Lamp Luminous Flux	350lm (3000K)		
	420lm (6500K)		
Lumen Maintenance 10000h	91%		
Lumen Maintenance 30000h	80%		


## Lumen Output Vs. Temperature

---

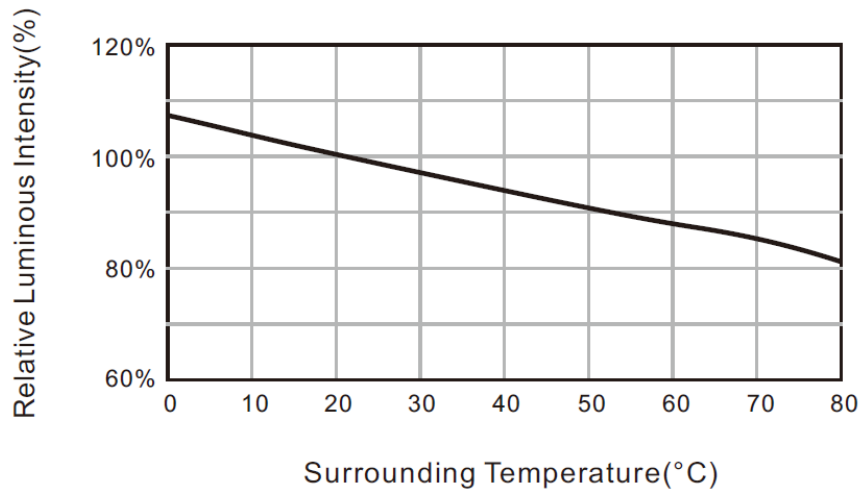


## Lumen Maintenance

---

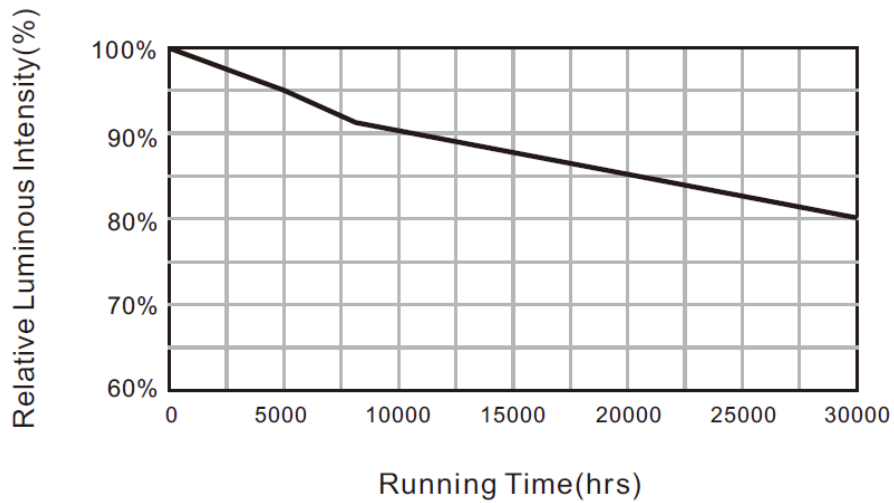


## Photometrics


3000K: ■ 6500K: ■

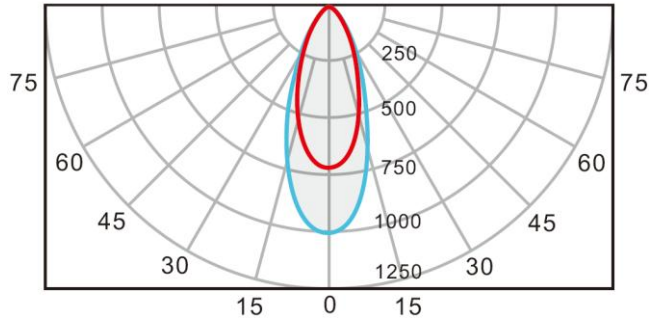

m	Beam Angle: 36°	Lux	∅cm
0.5		2800/4000	28
1.0		700/1000	56
2.0		175/250	112
3.0		77.7/111	168.5

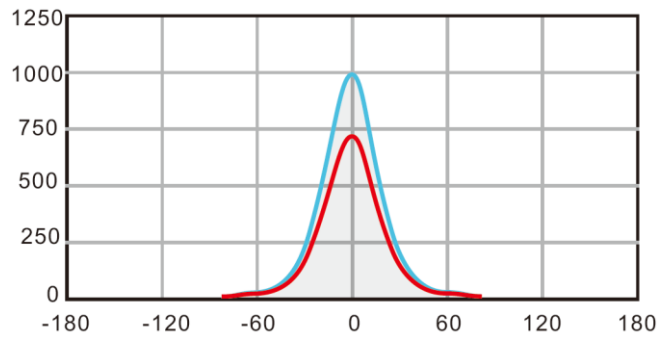

## Line Drawing

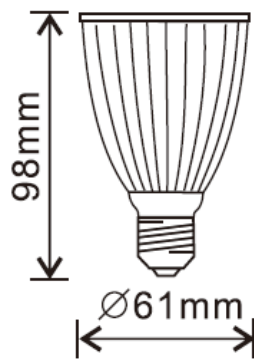


## Packaging

---

- 50 units per outer carton

## Dimension


---

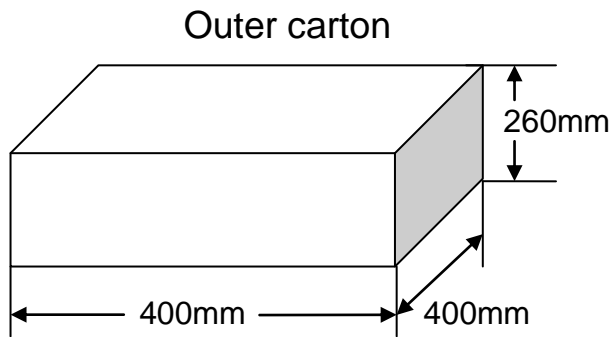

## Mark

---
 
### Outer carton



## Label

---

### Outer Carton (100\*70mm)

<b>Kosnic</b> <i>LED-P20</i>	
Product Code	<b>KLED07P20/E27-830</b>
Picking Code	<b>K</b>
Box Qty	<b>50</b>
Gross Weight	7.2kg
Dimension	400*400*260mm
Description	LED-P20, 7W, E27, 3000K

### Outer Carton (100\*70mm)

<b>Kosnic</b> <i>LED-P20</i>	
Product Code	<b>KLED07P20/E27-865</b>
Picking Code	<b>K</b>
Box Qty	<b>50</b>
Gross Weight	7.2kg
Dimension	400*400*260mm
Description	LED-P20, 7W, E27, 6500K