

Manhattan


freesat HD

Plaza HD•S2

HD Digital Satellite Receiver



Subscription Free TV in HD

Over 150 free TV & radio channels from freesat, with six TV channels in amazing HD.

And with On Demand TV including BBC iPlayer and ITV Player, you can catch up with the best of the week's TV, at a time that suits you.

BBC iPlayer **ITV PLAYER**

Compact Power

The successor to the award-winning Plaza HD•S, the HD•S2 is the most compact freesat HD receiver available, and comes bursting with unique features.


Easily create up to eight lists of your favourite channels, then use them to filter the Programme Guide, so you only see the ones you want to.

If over 150 freesat channels are not enough, you can automatically add hundreds more non-freesat channels, and combine them with freesat channels on the same favourites lists.

The Plaza HD•S2 even helps save you money thanks to its extremely low power consumption (less than ½W in standby), and comes recommended by the Energy Saving Trust.

Plaza HD•S2

HD Digital Satellite Receiver

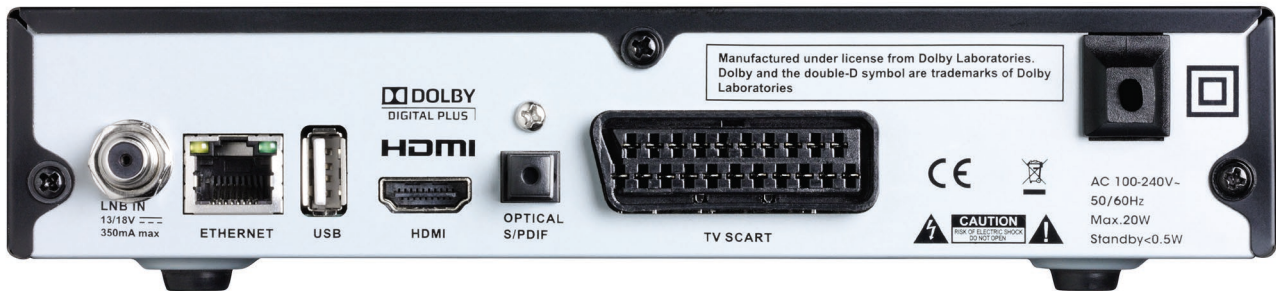

Features

- Over 150 digital channels
- 8-Day on-screen Programme Guide
- On Demand TV with BBC iPlayer & ITV Player
- Up to 8 favourites lists
- Auto scan of non-freesat channels
- Interactive TV & Digital Text
- Parental Control
- Energy Saving Trust recommended
- Audio Description capable
- Subtitles
- Last channel recall
- Supported resolutions: 576i, 576p, 720p, 1080i, 1080p
- Dolby Digital Plus

Included

- Remote control & batteries
- User Guide & Quick Start Guide
- HDMI cable

Connections

- LNB In • HDMI
- SCART • Optical S/PDIF
- Ethernet • USB

Tuner

- Input frequency: 950~2150MHz
- Input connector: F type, Female 75 ohm
- LNB supply: 14.0V / 18.0V (max 350mA), Short Circuit Protected
- Digital signal input level: -65 to -25 dBm

Power Requirements

- Mains input voltage: 100-240V AC~ 50/60Hz
- Power consumption: Max 20W (LNB with 350mA)
- Standby consumption: Less than 0.5W

Versions & Profiles

- HDMI: 1.3 • HDCP: 1.2 • USB: 2.0
- Audio Decoder: MPEG-1 Layer 1/2, MPEG-2 Layer 2, HE-AAC, AC-3 (Dolby Digital), E-AC-3 (DD Plus)
- Video Decoder: MPEG-2 MP@HL, MPEG-4 SP & ASP, H.264 MP 4.1, AVS, VC-1 MP@HL

Physical Specifications

- Width 210mm • Depth 147mm • Height 49mm
- Weight: 550g
- Operating temp: 0 to 40c
- Storage temp: -15 to 45c

