

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0016020037](#)  
**Status:** **Obsolete**  
**Description:** Board-In Crimp Terminal, Series 4811, Male, with Tin (Sn) Plated Brass Contact, 22-24 AWG, 2.54mm (.100") max. Insulation Diameter, 9.70mm (.380") Terminal Progression, Reel Packaged

**Documents:**  
[Drawing \(PDF\)](#)

**General**

Product Family	Crimp Terminals
Series	<a href="#">4811</a>
Application	Signal
Comments	Progression 9.70 (.380)
Crimp Quality Equipment	Yes
Product Name	Board-In Stand Alone Terminal

**Physical**

Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.54mm (.100") max.
Wire Size AWG	22, 24, 26
Wire Size mm <sup>2</sup>	N/A

**Material Info**

Old Part Number	4811-A-AA(P909)CB
-----------------	-------------------

**Reference - Drawing Numbers**

Product Specification	PS-4706-001
Sales Drawing	SD-4811-*


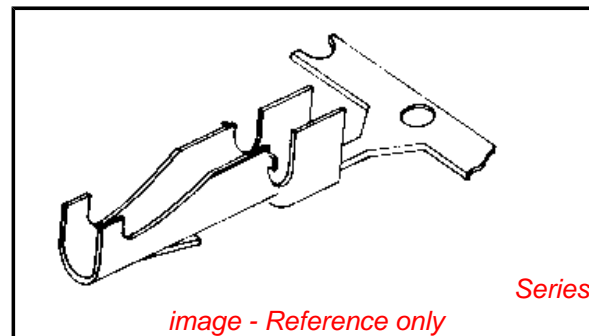


image - Reference only

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC**  
**Contains SVHC: No**  
**Low-Halogen Status**  
**Low-Halogen**

**China RoHS**

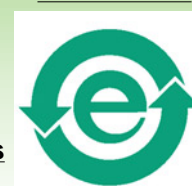

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

4811Series

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
Mini-Mac™ Applicator	<a href="#">0638925000</a>
Insertion Tool	<a href="#">0011020017</a>