

Compact size, flexible mounting options for ceiling, wall or bench

Durable steel construction for commercial and general purpose applications

Automatic ratchet lock holds cord at desired length and provides easy, smooth retraction of cord

Attached plug for power cord requires no wiring

**HBLC25163C**



Removable bracket allows reel to be dis-engaged from mount providing portability

Durable light weight non-metallic housing

40 Ft. of 12/3 cord for greater current carrying capacity

Triple tap outlet with supplemental over current protection

**HBLC40123TT**

**Commercial Cord Reels**

Description	Cable Feet (m)	Cable Type	Watts (Max)	Amps	Volts AC	Weight Lbs. (kg)	Catalog Number
Reel with triple tap outlet, black.	40 (12.2)	12/3 SJTW	1,875	15	125	9.0 (4.1)	<b>HBLC40123TT</b>
Reel with wire leads, black.	40 (12.2)	12/3 SJTW	1,875	15	125	9.0 (4.1)	<b>HBLC40123</b>
Reel with triple tap outlet, white.	30 (9.1)	16/3 SJT	1,250	15	125	8.5 (3.9)	<b>HBLC30163TT</b>
Reel with a Hubbell HBL5969VBLK connector, yellow.	25 (7.6)	16/3 SJT	1,250	10	125	8.5 (3.9)	<b>HBLC25163C</b>
Reel with wire leads, yellow.	25 (7.6)	16/3 SJT	1,250	10	125	8.5 (3.9)	<b>HBLC25163*</b>

Note: Reels supplied with 2 ft. power supply cord and molded on straight blade 15A plug.  
 \*UL Listed only.



**HBLC40123TT**




**HBLC25163C**

**Specifications**

Listing/Certification	UL 355.
Environment	Dry, indoor, non-hazardous locations.
Incandescent Lamp	75 watt max., auto switch, no receptacle; 100 watt max. bulb, with receptacle.
Fluorescent Lamp	10A/1200W max. with in-line receptacle; 13 watt without receptacle.

**Dimensions**

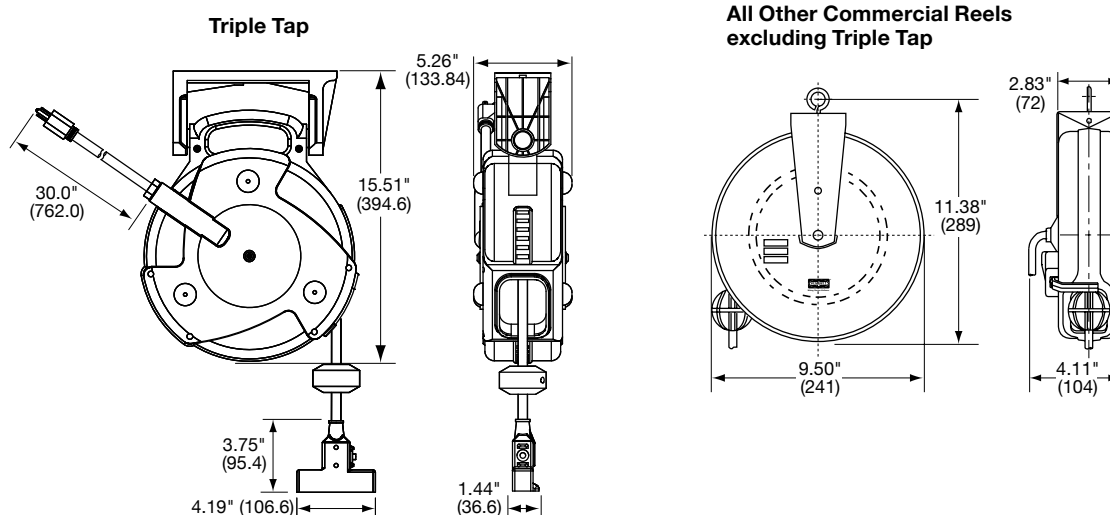

Dimensions in Inches (mm)