

**T3-BOX TELEPHONE CABINET, TYPE 3R**

**INDUSTRY STANDARDS**

UL 50, 50E Listed; Type 3R; File No. E27567  
 UL 497 / 1863 Listed; File No. E230874  
 cUL Listed per CSA C22.2 No 94; Type 3R; File No. E27567

NEMA Type 3R  
 IEC 60529 IP32

**APPLICATION**

Use T-3 Box Telephone Cabinets to mount and protect telephone terminations, telecommunications circuit accessories, cross-connect terminal block assemblies, maintenance terminal modules, cable-splice enclosures, network interface devices, wire-guide assemblies and telephone protectors in outdoor applications.

**FEATURES**

- Lift-off hinges
- 4-position grounding bar #14-2/0
- Tamper-resistant quarter-turn latch
- 7-mm square drive; use key accessory CLKSM7 or 5/16 12-point socket
- Padlock hasp
- Standard knockouts

**SPECIFICATIONS**

- 16 or 14 gauge galvanized steel
- 3/4-in.-thick plywood panel

**FINISH**

ANSI 61 gray polyester powder paint inside and outside.


**ACCESSORIES**

*See also Accessories.*  
 Locking T Handle  
 Large Enclosure Door Stop Kit  
 Lock Inserts  
 Touch-Up Paint

**BULLETIN: T90R3**

## Standard Product

Catalog Number	AxBxC in./mm	Door	F in./mm	Panel Size D x E in./mm	Conduit Pattern
ATC12R145	12.00 x 14.00 x 5.00 305 x 356 x 127	Single	4.00 102	9.00 x 11.00 229 x 279	G-H-I
ATC36R366	36.00 x 36.00 x 6.00 914 x 914 x 152	Single	13.50 343	33.00 x 33.00 838 x 838	C-D-E-F-G-H-I-J-K-L-M
ATC26R248	26.00 x 24.00 x 8.00 660 x 610 x 203	Single	7.50 191	23.00 x 21.00 584 x 533	E-F-G-H-I-J-K
ATC36R248	36.00 x 24.00 x 8.00 914 x 610 x 203	Single	7.50 191	33.00 x 21.00 838 x 533	E-F-G-H-I-J-K
ATC36R308	36.00 x 30.00 x 8.00 914 x 763 x 203	Single	10.50 267	33.00 x 27.00 838 x 686	D-E-F-G-H-I-J-K-L
ATC36R369	36.00 x 36.00 x 9.00 914 x 914 x 229	Single	13.50 343	33.00 x 33.00 838 x 838	C-D-E-F-G-H-I-J-K-L-M
ATC42R369	42.00 x 36.00 x 9.00 1066 x 914 x 229	Double	13.50 343	39.00 x 33.00 911 x 838	C-D-E-F-G-H-I-J-K-L-M
ATC48R369	48.00 x 36.00 x 9.00 1220 x 914 x 229	Double	13.50 343	45.00 x 33.00 1143 x 838	C-D-E-F-G-H-I-J-K-L-M
ATC48R489	48.00 x 48.00 x 9.00 1219 x 1219 x 229	Double	19.50 495	45.00 x 45.00 1143 x 1143	A-B-C-D-E-F-G-H-I-J-K-L-M-O
ATC36R3612	36.00 x 36.00 x 12.00 914 x 914 x 305	Single	13.50 343	33.00 x 33.00 838 x 838	C-D-E-F-G-H-I-J-K-L-M

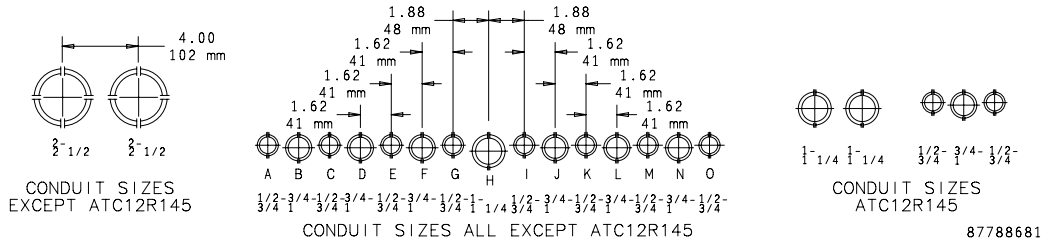

87788681

