


MECHANICAL DETAILS

Shell Style Model	FG* : Straight plug
Keying	3 keys (beta=155, gamma=50, plug: female contacts, receptacle: male contacts)
Housing Material	Environment friendly aluminium (nickel plated, anthracite color) shell and nut, other pieces bronze/brass
Cable Fixing	0 - 0 mm
Variant 2	:

	A	B	L	M
Mm.	12	9	27.5	18
In.	0.47	0.35	1.08	0.71

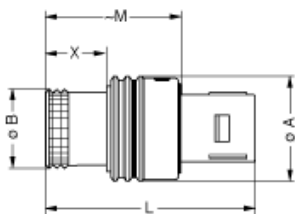

Available Download

 [f_series.pdf](#)


PERFORMANCE DETAIL

Insert	0F.303 : 3 Low Voltage
Insulator	L: PEEK
Specifications	
Contact Type:	Crimp
Max. Matings:	5000
Contact	30 N
Contact Dia.:	0.9 mm (0.035in)
Bucket Dia.:	1.1 mm (0.043in)
Min. Conductor:	0.25 mm ² (AWG 24)
Max. Conductor:	0.5 mm ² (AWG 20)
R (max):	4.8 mOhm
Positioner:	DCE.91.090.BVM







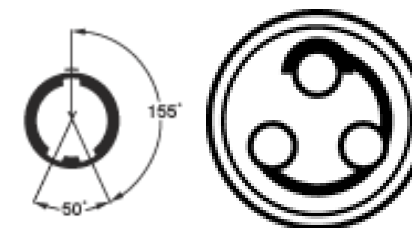

OTHER CHARACTERISTICS

Endurance (Shell)	Endurance (Shell):
Temp (min)	-15°C
Temp (max)	+200°C
Humidity (max):	<=95% [at 60 deg C /140 F]
Vibration:	15 g [10 Hz - 2000 Hz]
Shock Resistance:	100 g [6 ms]
Climatical	15/200/21 (Aluminium shell)
IP Rating	67



Related links

-  [Contact](#)
-  [Quote Request](#)
-  [Catalogs Downloads](#)
-  [Catalogs Requests](#)
-  [Sample Request](#)
-  [3D drawings](#)