

# MAX CASES

**IP67**  
RATING

**WATERPROOF  
& DUSTPROOF**

**100%  
MADE  
IN ITALY**



Le valigette MAX sono certificate IP67 per garantirne la resistenza all'acqua e alle polveri. Il campo di applicazione di tali valigie spazia dalla nautica, fotografia, subacquea, caccia, pesca, corpi speciali, industria manifatturiera in generale e tutti quei settori dove è richiesta un'eccezionale resistenza agli urti e agli agenti atmosferici

*MAX cases are IP67 certified, tough, durable and reliable. They may be used in a variety of applications, ranging from marine, photography, scuba diving, hunting, fishing, special corps and even the manufacturing industry. These cases offer superior protection from the elements, water, dust and impacts, making them suitable for a wide array of sectors and applications.*

1. Guarnizione ermetica
2. Valvola automatica di pressurizzazione
3. Chiusure di sicurezza a doppio step per facilitare l'apertura
4. Manico morbido prodotto con uno speciale compound per migliorarne la presa ed il comfort
5. Doppia predisposizione lucchetto
6. Predisposizione cintura a tracolla
7. Sistema di impilabilità
8. Pareti molto spesse per garantire la resistenza agli urti
9. Punti di fissaggio per varie applicazioni
10. Cerniera lungo tutto il profilo della valigia
11. Perni in nylon, nessun problema di corrosione
12. Spugne cubettate nel fondo e bugnate nel coperchio di serie. Spugne sagomate disponibili su richiesta
13. Coperchio serigrafabile
14. Predisposizione per etichetta resinata

1. Watertight seal around lid
2. Automatic pressure release valve
3. Easy to open double throw latches
4. Load tested soft grip handle
5. Holes for double padlocking
6. Holes for shoulder strap
7. Stackable interlocking system
8. Thick body material
9. Extra fixing points
10. Full length hinges
11. Corrosion free nylon pins
12. Cubed foams in the bottom and convoluted foam in the lid available as standard. Custom foam available upon request
13. Screen printing space on the lid
14. Rectangular resin label space on lid





## MAX235 H105



DIM ESTERNE / EXTERNAL DIM.:	258 x 243 x H117,5 mm 10.16 x 9.56 x H4.62 inch.
DIM INTERNE / INTERNAL DIM.:	235 x 180 x H106 mm 9.25 x 7.08 x H4.17 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	25 + 81 mm 0.98 + 3.19 inch.
PESO / WEIGHT:	1000 g
COLORI / COLORS:	
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams

## MAX430



DIM ESTERNE / EXTERNAL DIM.:	464 x 366 x H176 mm 18.27 x 14.41 x H6.93 inch.
DIM INTERNE / INTERNAL DIM.:	426 x 290 x H159 mm 16.77 x 11.42 x H6.26 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	45 + 114 mm 1.77 + 4.49 inch.
PESO / WEIGHT:	2780 g
COLORI / COLORS:	
ACCESSORI / ACCESSORIES:	spugne cubettate / cubed foams tasca / lid organizer divisorie imbottite / padded dividers tracolla imbottita / padded shoulder strap

## MAX235 H155



DIM ESTERNE / EXTERNAL DIM.:	258 x 243 x H167,5 mm 10.16 x 9.56 x H6.59 inch.
DIM INTERNE / INTERNAL DIM.:	235 x 180 x H156 mm 9.25 x 7.08 x H6.14 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	25 + 131 mm 0.98 + 5.16 inch.
PESO / WEIGHT:	1200 g
COLORI / COLORS:	
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams

## MAX300



DIM ESTERNE / EXTERNAL DIM.:	336 x 300 x H148 mm 13.23 x 11.81 x H5.83 inch.
DIM INTERNE / INTERNAL DIM.:	300 x 225 x H132 mm 11.81 x 8.86 x H5.20 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	33 + 99 mm 1.30 + 3.90 inch.
PESO / WEIGHT:	1750 g
COLORI / COLORS:	
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams


## MAX505



DIM ESTERNE / EXTERNAL DIM.:	555 x 428 x H211 mm 21.85 x 16.85 x H8.31 inch.
DIM INTERNE / INTERNAL DIM.:	500 x 350 x H194 mm 19.69 x 13.78 x H7.64 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	58 + 136 mm 2.28 + 5.36 inch.
PESO / WEIGHT:	3860 g
COLORI / COLORS:	
ACCESSORI / ACCESSORIES:	spugne cubettate / cubed foams tasca / lid organizer divisorie imbottite / padded dividers tracolla imbottita / padded shoulder strap



Aggancio tracolla  
Shoulder strap hook

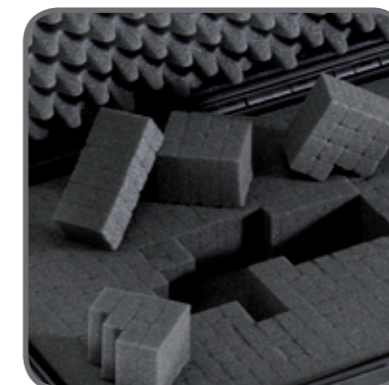

Spugne cubettate  
Cubed foams



Tasca multiuso  
Internal pocket organizer

## MAX620 H250

DIM ESTERNE / EXTERNAL DIM.:	687 x 528 x 276 mm 27.05 x 20.79 x 10.86 inch.
DIM INTERNE / INTERNAL DIM.:	620 x 460 x 250 mm 24.41 x 18.11 x 9.84 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	60 + 190 mm 2.36 + 7.48 inch.
PESO / WEIGHT:	6900 g
COLORI / COLORS:	■
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams



## MAX620 H340

DIM ESTERNE / EXTERNAL DIM.:	687 x 528 x 366 mm 27.05 x 20.79 x 14.41 inch.
DIM INTERNE / INTERNAL DIM.:	620 x 460 x 340 mm 24.41 x 18.11 x 13.38 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	60 + 280 mm 2.36 + 11.02 inch.
PESO / WEIGHT:	8000 g
COLORI / COLORS:	■
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams



## MAX620 H250TR

DIM ESTERNE / EXTERNAL DIM.:	687 x 528 x 286 mm 27.05 x 20.79 x 11.26 inch.
DIM INTERNE / INTERNAL DIM.:	620 x 460 x 250 mm 24.41 x 18.11 x 9.84 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	60 + 190 mm 2.36 + 7.48 inch.
PESO / WEIGHT:	8200 g
COLORI / COLORS:	■
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams



## MAX620 H340TR

DIM ESTERNE / EXTERNAL DIM.:	687 x 528 x 376 mm 27.05 x 20.79 x 14.80 inch.
DIM INTERNE / INTERNAL DIM.:	620 x 460 x 340 mm 24.41 x 18.11 x 13.38 inch.
PROFONDITÀ COPERCHIO-FONDO / LID-BOTTOM DEPTH:	60 + 280 mm 2.36 + 11.02 inch.
PESO / WEIGHT:	9300 g
COLORI / COLORS:	■
ACCESSORI / ACCESSORIES:	spugne cubettate - cubed foams



Maniglia telescopica disponibile solo sui modelli "TR"  
Extendable handle available only on TR models

Maniglia telescopica disponibile solo sui modelli "TR"  
Extendable handle available only on TR models



**RUOTE CON ASSALE IN ACCIAIO INOX**  
WHEELS WITH STAINLESS STEEL PIN

**MANIGLIA LATERALE SU ENTRAMBI I LATI**  
SIDE HANDLES

**RETRO-MANIGLIA TELESCOPICA A SCOMPARSA**  
EXTENDABLE HANDLE





## VALIGIE CON SPUGNE CUBETTATE CUBED FOAM CASES



Configurazione interno in spugna  
Foam set configuration

Articolo Article	Spugna liscia Base foam	Spugne cubettate Cubed foams	Spugna bugnata Convuluted foam
<b>MAX235 H105S</b>	1 x 20mm 1 x 0.79inch.	2 x 30mm 2 x 1.18inch.	1 x 22mm 1 x 0.87inch.
<b>MAX235 H155S</b>	1 x 30mm 1 x 1.18inch.	2 x 50mm 2 x 1.97inch.	1 x 22mm 1 x 0.87inch.
<b>MAX300S</b>	1 x 20mm 1 x 0.79inch.	2 x 35mm 2 x 1.38inch.	1 x 35mm 1 x 1.38inch.
<b>MAX430S</b>	1 x 20mm 1 x 0.79inch.	2 x 40mm 2 x 1.57inch.	1 x 45mm 1 x 1.77inch.
<b>MAX505S</b>	1 x 20mm 1 x 0.79inch.	2 x 55mm 2 x 2.16inch.	1 x 50mm 1 x 1.97inch.
<b>MAX620 H250S</b>	1 x 40mm 1 x 1.57inch.	3 x 50mm 3 x 1.97inch.	1 x 50mm 1 x 1.97inch.
<b>MAX620 H340S</b>	1 x 40mm 1 x 1.57inch.	2 x 55mm + 2 x 65mm 2 x 2.16inch. + 2 x 2.56inch.	1 x 50mm 1 x 1.97inch.

## PORTAUTENSILI TOOL CASES

Disponibili su MAX430 - MAX505 / Available for MAX430 - MAX505



### MAX430 PU

Tasca + pannello portautensili  
Pocket organizer + tool panel



### MAX505 PU

Tasca + doppio pannello portautensili  
Pocket organizer + double tool panel