



PAA.M0.6GL.CC39J

MECHANICAL DETAILS

Shell Style Model PA* : Straight plug with cable collet


Keying 2 keys (alpha=40; Plug: male contacts; Receptacle: female contacts)

Housing Material PSU (Polysulfone), gray

Cable Fixing 2.7 - 3.9 mm

Variant 2 J : Yellow collet nut

| | A | L |
|-----|------|------|
| Mm. | 14 | 45 |
| In. | 0.55 | 1.77 |

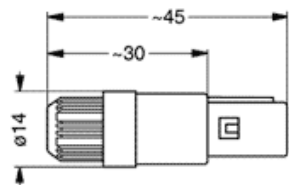

PERFORMANCE DETAIL

Insert 1P.M06 : 6 Low Voltage

Insulator

Specifications

Contact Type: Crimp

Max. Matings: 2000

Contact 26 N

Contact Dia.: 0.7 mm (0.0275in)

Min. Conductor: 0.14 mm² (AWG 26)

Max. Conductor: 0.34 mm² (AWG 22)

R (max): 6.5 mOhm

Positioner: DCE.91.075.BVD



OTHER CHARACTERISTICS

Shell Style/Model Libellé

F ret (min): 50 N

F ret (max): 150 N

IP Rating 50

