



PAG.M0.4GL.AC52A

MECHANICAL DETAILS

Shell Style Model PA* : Straight plug with cable collet


Keying 1 key (alpha=0; Plug: male contact; Receptacle: female contact)

Housing Material PSU (Polysulfone), gray

Cable Fixing 4 - 5.2 mm

Variant 2 A : Blue collet nut

	A	L
Mm.	14	45
In.	0.55	1.77

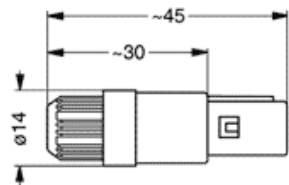

PERFORMANCE DETAIL

Insert 1P.M04 : 4 Low Voltage

Insulator

Specifications

Contact Type: Solder

Max. Matings: 2000

Contact Dia.: 0.9 mm (0.035in)

Bucket Dia.: 0.8 mm (0.031in)

Max. Solid 0.34 mm² (AWG 22)

Max. Stranded 0.34 mm² (AWG 22)

R (max): 4.5 mOhm



OTHER CHARACTERISTICS

Shell Style/Model Libellé

F ret (min): 50 N

F ret (max): 150 N

IP Rating 50

