



PAG.M0.4GL.CC52Z

(Obsolete)

MECHANICAL DETAILS

Shell Style Model PA* : Straight plug with cable collet


Keying 1 key (alpha=0; Plug: male contact; Receptacle: female contact)

Housing Material PSU (Polysulfone), gray

Cable Fixing 4 - 5.2 mm

Variant 2 :

	A	L
Mm.	14	45
In.	0.55	1.77

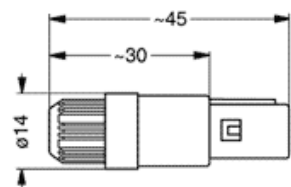

PERFORMANCE DETAIL

Insert 1P.M04 : 4 Low Voltage

Insulator

Specifications

Contact Type: Crimp

Max. Matings: 2000

Contact 24 N

Contact Dia.: 0.9 mm (0.0354in)

Min. Conductor: 0.5 mm² (AWG 20)

Max. Conductor: 0.25 mm² (AWG 24)

R (max): 4.5 mOhm

Positioner: DCE.91.095.BVD



OTHER CHARACTERISTICS

Shell Style/Model Libellé

F ret (min): 50 N

F ret (max): 150 N

IP Rating 50

