

Part Number **3-661-15**

Special pliers made from high grade special steel for extremely high requirements;
by precision inductiv hardness process blades achieve up to 65 HRC

Box joint

precise jaw adjustment without backlash

fine polished and bright burnished surface

Double leaf spring from stainless steel

Ergonomically formed bicoloured hand guard from dissipative anti-slide material

The pliers of this programm have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas.



Description: Carbide mini side cutters EUROline-Conductive , rounded, for continuous heavy work, with inserted carbide cutting edges, also for tough nickel and electrode wires

Characteristics:

Blade Finish **Semi Flush**



Cutting capacity soft wire **Ø 2.0 mm**

Cutting capacity medium wire **Ø 1.5 mm**


cutting capacity hard wire **Ø 1.0 mm**

Ø 0.6 mm for Piano wire

A - Head width **11 mm**

B - Head thickness **7 mm**

C - Blade / jaw length **11 mm**

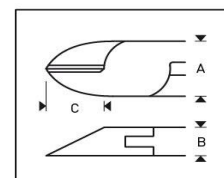

Length **120 mm**

Weight **70 g**

Customs Tariff No. **82032000**



EAN-No. **4250838502719**

Link to catalogue page www.bernstein-werkzeuge.de/Katalogseiten/EUROline-Conductive_English.pdf

Link to image <http://www.bernstein-werkzeuge.de/Artikelbilder/03/3-661-15.jpg>

Image file **3-661-15.jpg**

Keywords **pliers; electronic pliers; side cutters**