

**Part Number** 33-215

**INOX HIGH - GRADE STEEL PLIERS**

for use in cleanrooms (autoclavable) antiseptic or in ESD protected areas. Stainless steel, swaged, box joint construction with screwed stainless double leaf spring. Extremely fine polished, abrasionproof, easy to clean, on request with inserted carbide cutting edges, on request with ESD hand guard.

The perfect pliers for works in following industries: aerospace - chemical - electronic - medical and dental technique - food production - shipbuilding - oil and gas production



**Article description** Side cutters with very slim rounded head


**Characteristics:**

blade Semi Flush



Cutting value soft wire Ø 1.1 mm  
Cutting value medium hard wire Ø 0.6 mm  
Cutting value hard wire Ø 0.2 mm

A - Head width 11 mm  
B - Head thickness 7.5 mm  
C - Length of blade/jaws 12 mm

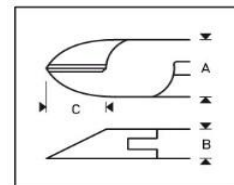

Length 115 mm

Weight 53 g

Customs Tariff Number: 82032000

EAN Number: 4250838503631



Link to catalogue page: [www.bernstein-werkzeuge.de/Katalogseiten/INOX\\_English.pdf](http://www.bernstein-werkzeuge.de/Katalogseiten/INOX_English.pdf)

Link to image: <http://www.bernstein-werkzeuge.de/Artikelbilder/03/33-215.jpg>

Image file: [33-215.jpg](http://www.bernstein-werkzeuge.de/Artikelbilder/03/33-215.jpg)

Keywords: pliers; electronic pliers; high - grade steel pliers