


Sample set - SAMPLE PTSM 0,5/ 7-HH-2,5-SMD - 1786099

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Header, Nominal current: 6 A, Rated voltage (III/2): 160 V, Number of positions: 7, Pitch: 2.5 mm, Color: black, Contact surface: Tin, Assembly: SMD/THT/THR



Key commercial data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 046356 572224
Weight per Piece (excluding packing)	1.69 g
Custom tariff number	85369010
Country of origin	Germany
Product key	AACMBA

Technical data

Product type	Printed circuit board housing
Rated voltage (IEC)	160
Rated current (IEC)	6
Mounting type	SMD/THT/THR
Number of positions	7
Pitch	2.5 mm
Levels	Single-level
Type of locking	Without

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701

Sample set - SAMPLE PTSM 0,5/ 7-HH-2,5-SMD - 1786099

Classifications

eCl@ss

eCl@ss 5.1	27260701
eCl@ss 6.0	27261101
eCl@ss 7.0	27440401
eCl@ss 8.0	27440402

ETIM


ETIM 3.0	EC001121
ETIM 4.0	EC002637
ETIM 5.0	EC002637

UNSPSC


UNSPSC 6.01	30211810
UNSPSC 7.0901	39121409
UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	39121409

Drawings

Drilling diagram

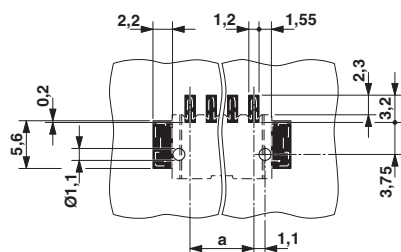

Diagram

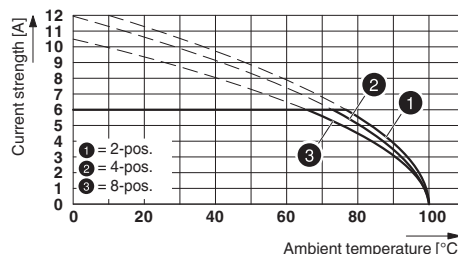

Derating curve for: PTSM 0,5/...-P-2,5 with PTSM 0,5/...-HH-2,5-SMD R..

Dimensioned drawing

