

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **505070-1610**
Status: **Active**
Overview: SlimStack™ 0.35mm pitch Board-to-Board Connectors
Description: 0.35mm Pitch SlimStack Armor™ Board-to-Board Plug Connector, Surface Mount, Dual Row, Vertical, 0.60mm Stacking Height, 2.00mm Width, 16 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification SPK-505070-001 \(PDF\)](#)

General

Product Family	PCB Headers
Series	<u>505070</u>
Application	Board-to-Board
Overview	<u>SlimStack™ 0.35mm pitch Board-to-Board Connectors</u>
Product Name	SlimStack Armor™
UPC	887191917115

Physical

Breakaway	No
Circuits (Loaded)	16
Circuits (maximum)	16
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Compliant	No
Mated Height	0.60mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	4.829/mg
Number of Rows	2
Orientation	Vertical
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.35mm
Polarized to Mating Part	No
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40°C to +85°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	.3A
Voltage - Maximum	50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-505070-001
Sales Drawing	SD-505070-001, SD-505070-002

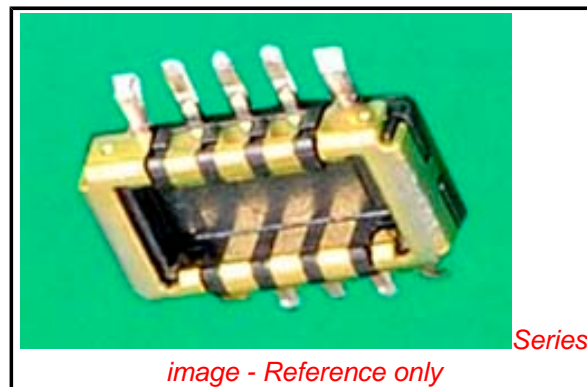


image - Reference only

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

505070Series

Mates With

505066 0.35mm Pitch SlimStack Armor™ Board-to-Board Receptacle